

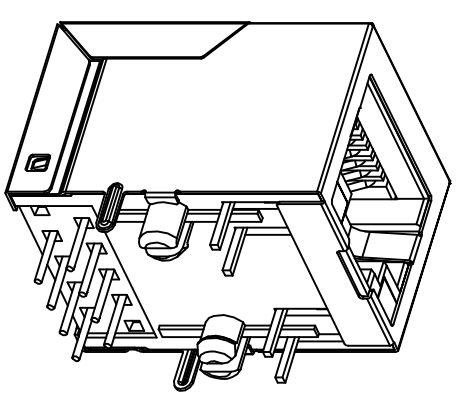


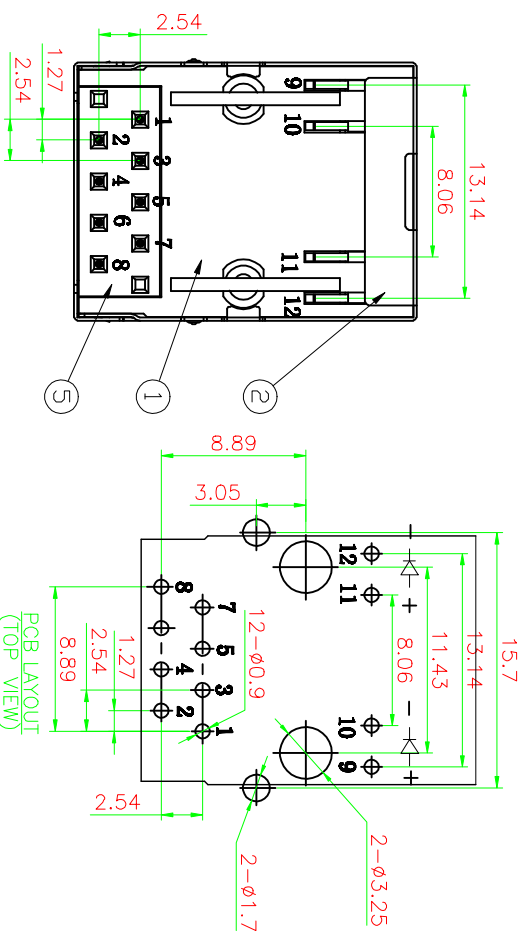

General Specification
Current Rating: 1.5A DC /Contact, 20A DC for LED signals
Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature -20°C~+70°C
Industrial Temperature -40°C~+85°C
Humidity: 20%~70%
Contact Resistance: ≤30mΩ
Insulation Resistance: ≥500MΩ
Dielectric Strength: 100V AC/1000V Min
Withstanding Voltage: 100V AC/1000V Min
Durability: 750 Cycles Min

Material Specification
Housing: Thermoplastic, UL94V-0
Contact: Alloy Copper
Shield: Alloy Copper
Please refer to the customer drawing when customer has specified

网络插座外形图

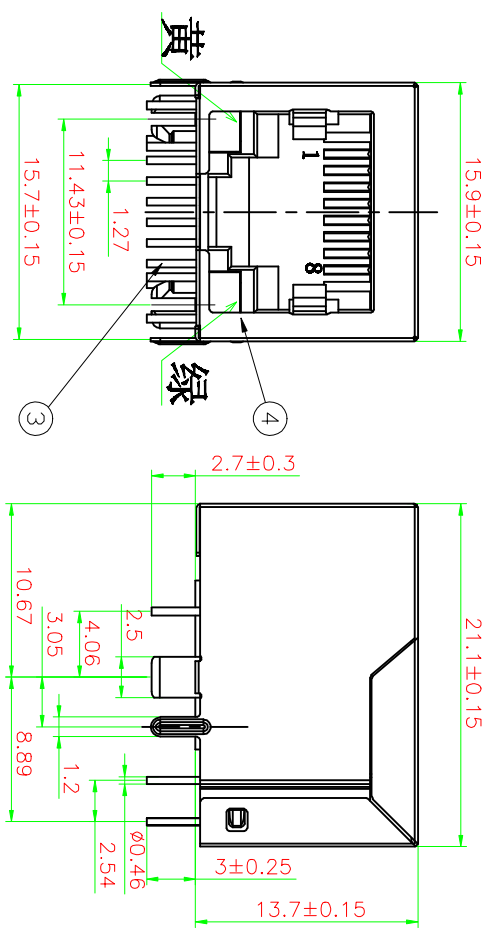

温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

序号	名称	材料	数量	备注
1	后盖	PA46	1	BLACK
2	LED灯	树脂/FE	2	NI/AG
3	插针	PHOSPHOR BRONZE	8	FU"
4	外壳	ABS	1	NI
5	底座	PA46	1	BLACK

绘图:	日期:
审核:	日期:
批准:	日期:

一般公差	公差	公差	公差
30~	±0.25	10~30	±0.20
10~30	±0.20	10~30	±0.15
角度:	±2°	角度:	±2°

品名:	规格:	图号:
RCR-59-01 (带灯无弹后脚3.05)	5901-8Y07010AB30 (RC00226)	RJ45

单位:mm	比例: 1:1	纸张: A4
-------	---------	--------

版本:	1 of 1
-----	--------

内部使用, 不得私自复印
