
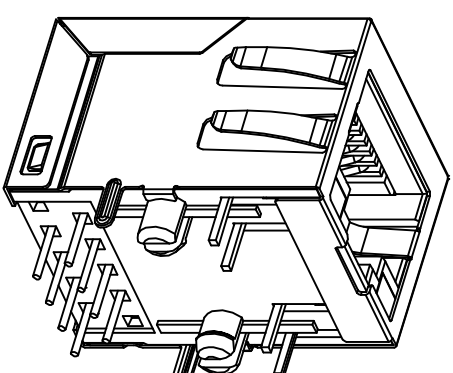
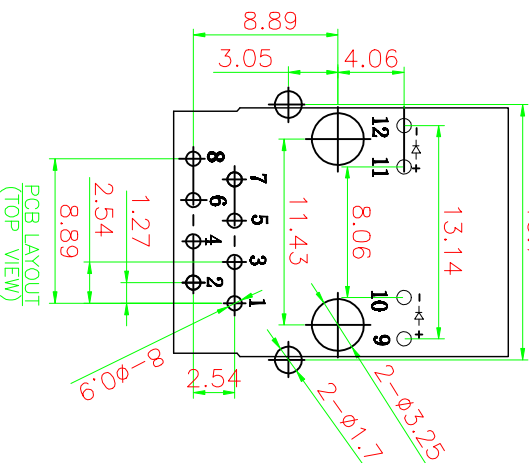
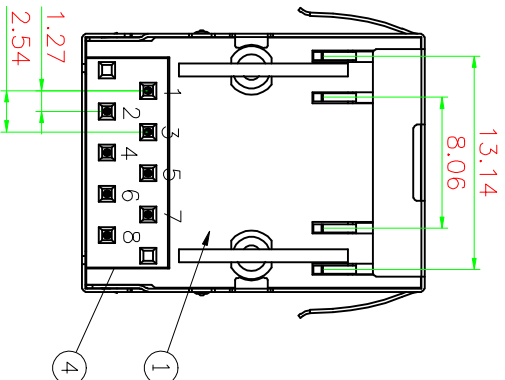
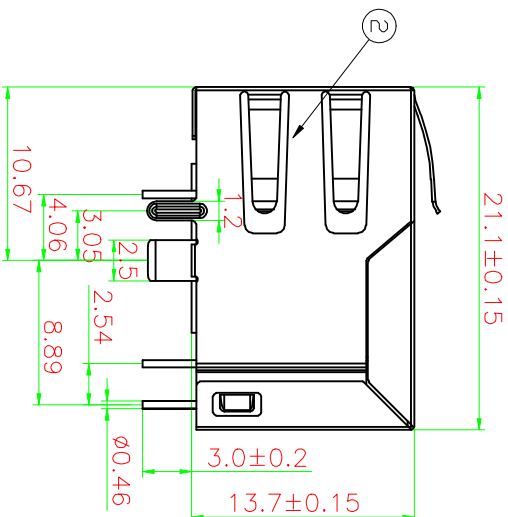


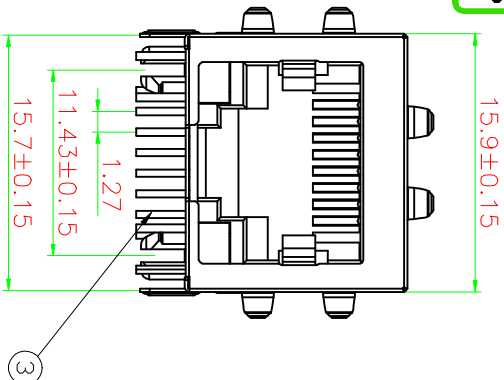

General Specification
Current Rating:1.6A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment: -20℃~+70℃
Standard Temperature: -40℃~+85℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Bending And Unbending Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermoplastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customers drawing when customer has specified

网络插座外形图

绘图: 吴鹏飞 日期: 2023.3.11

审核: 陈德 日期:

批准: 朱生 日期:



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

品名: RCH-59-01(带灯带弹前脚3.05)
料号: 5901-8YG03410AB30 (RC00228)
型号: RJ45
图号:

公差: ±0.25
料号: 10~30 ±0.30
角度: ±0.15
角度: ±2°
版本: 1 of 1
单位:mm
比例: 1:1
纸张: A4

1 2 3 4 5 6 7 8 9 10 11
A B C D E
必须标注上视图尺寸
A/0
新出版发行
变更履历
变更单号
该图面供温州瑞川电子有限公司内部使用,不得私自复印