

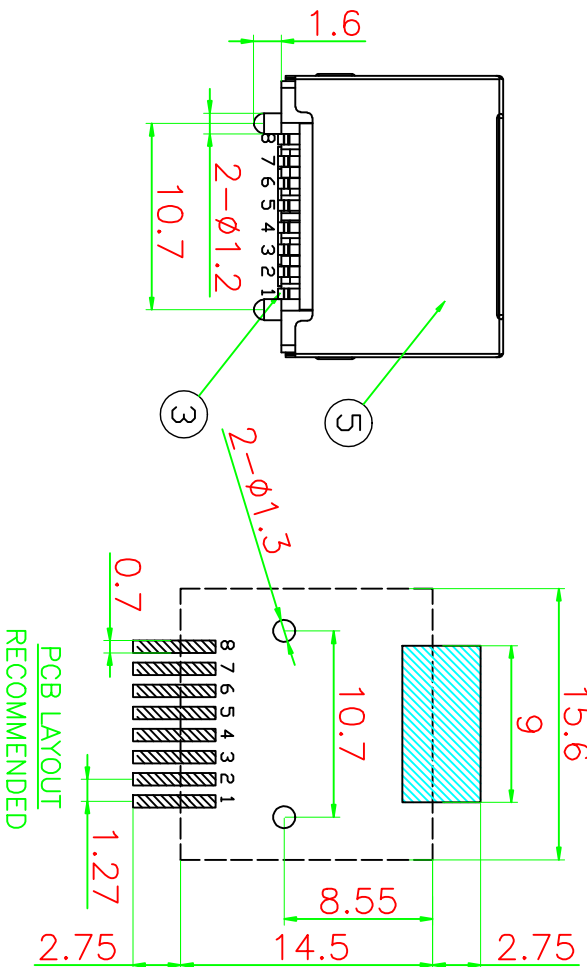
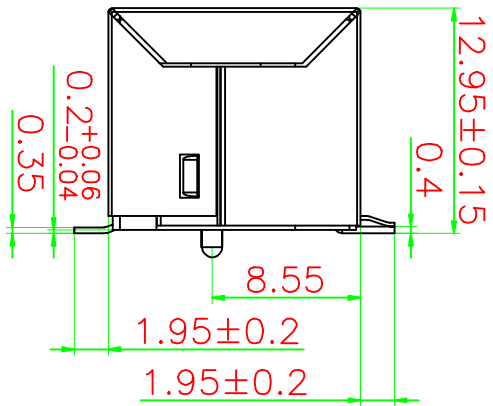


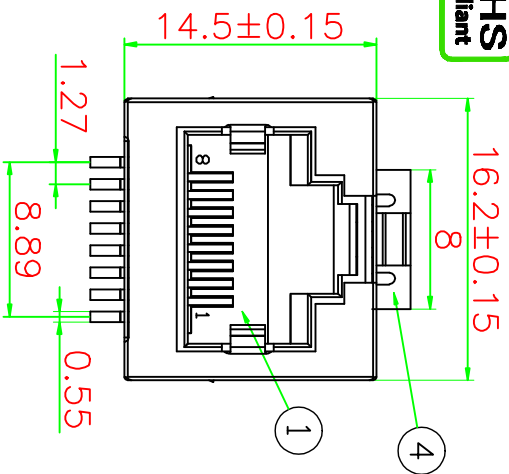

PCB LAYOUT  
RECOMMENDED

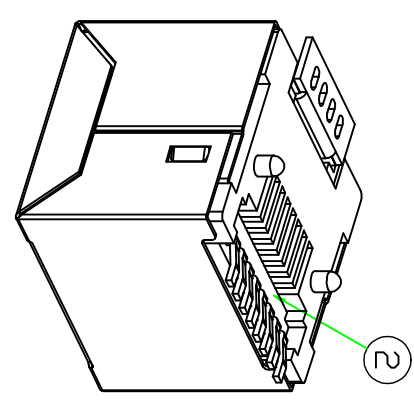

General Specification  
Current Rating: 1.5A DC /Contact, 20mA DC for LED signals  
Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals  
Operating Environment  
Standard Temperature: -20℃~+70℃  
Industrial Temperature: -40℃~+85℃  
Humidity: 20~70%  
Contact Resistance: ≤30mΩ  
Insulation Resistance: ≥500MΩ  
Dielectric Strength: 500V AC/(50HZ)/Min  
Mating And Umating Force: 3~20N  
Durability: 750 Cycles Min

Material Specification  
Housing :Thermo-plastic, UL94V-0.  
Contact :Alloy Copper  
Shield :Alloy Copper

Please refer to the customer drawing when customer has specified

|    |     |                 |    |       |    |
|----|-----|-----------------|----|-------|----|
| 5  | 屏蔽壳 | H62             | 1  | MI    |    |
| 4  | 定位片 | H62             | 1  | Ni/Sn |    |
| 3  | 插针  | PHOSPHOR BRONZE | 8  | 3U"   |    |
| 2  | 后盖  | LCP             | 1  | BLACK |    |
| 1  | 塑座  | LCP             | 1  | BLACK |    |
| 序号 | 名称  | 材料              | 数量 | 镀层/颜色 | 备注 |

网络插座外形图



温州瑞川电子有限公司  
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

|      |     |    |          |       |                                 |        |
|------|-----|----|----------|-------|---------------------------------|--------|
| 图号   | 吴素飞 | 日期 | 2022.4.8 | 品名    | RJH-SR-35-12TP-无灯无弹             |        |
| 审核   | 陈伟  | 日期 |          | 料号    | SP3512TP-800020031B20 (WR44133) |        |
| 核准   | 陈伟  | 日期 |          | 型号    | RJ45                            |        |
| 日期   |     |    |          | 图号    |                                 |        |
| 变更单号 |     | 绘制 |          | 单位:mm | 比例: 1:1                         | 纸张: A4 |
| 变更履历 |     | 日期 |          | 版本    |                                 |        |
| 版本   | A/0 |    |          |       |                                 |        |