


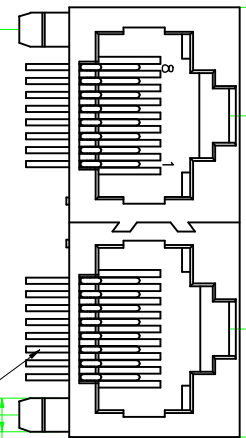

31.75±0.15

15.75




28.45±0.15

2.5

③

15±0.15

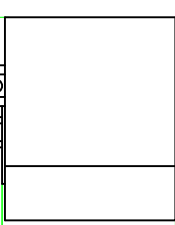

5

φ3.2

φ0.46

1.78

5.05


4.32

3±0.25

12.8±0.15


General Specification
Current Rating:1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment -20℃~+70℃
Standard Temperature: -40℃~+85℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Mating And unmating Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

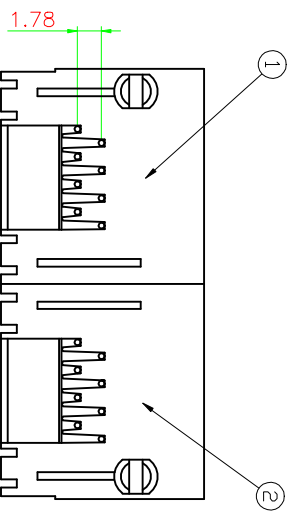

①

②

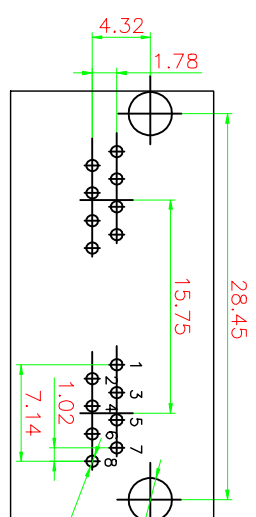

28.45

1.78

4.32


15.75

2-φ3.25

8-φ0.9

1.02

7.14

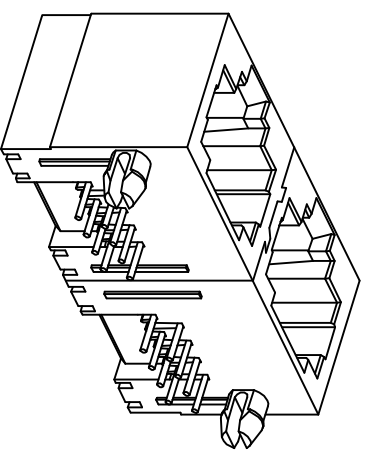

PCB LAYOUT
RECOMMENDED

网络插座外形图

绘图: 吴鹏飞 日期: 2022.4.11
审核: 陈伟 日期:
核准: 日期:



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

序号	名称	材料	数量	镀层/颜色	备注
3	插针	PHOSPHOR BRONZE	16	FU"	
2	右分体	PBT	1	YELLOW	
1	左分体	PBT	1	YELLOW	

一般公差
30~ ±0.25
10~30 ±0.20
~10 ±0.15
角度: ±2°
版本: 1 of 1
单位:mm 比例: 1:1 纸张: A4

品名: RCH-56-31-12(全塑无灯)
料号: 563112-80000010PY30 (RC01062)
型号: RJ45 图号:

版本: A/0

变更履历

变更单号

绘制

日期

核准

日期

1

2

3

该图面供温州瑞川电子有限公司内部使用,不得私自复印