
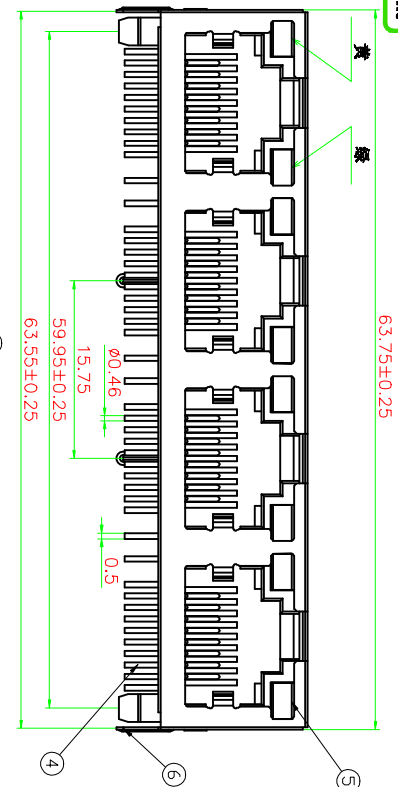


General Specification
Current Rating:1.6A DC /Contact, 20A DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/50HZ/Min
Withstanding Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

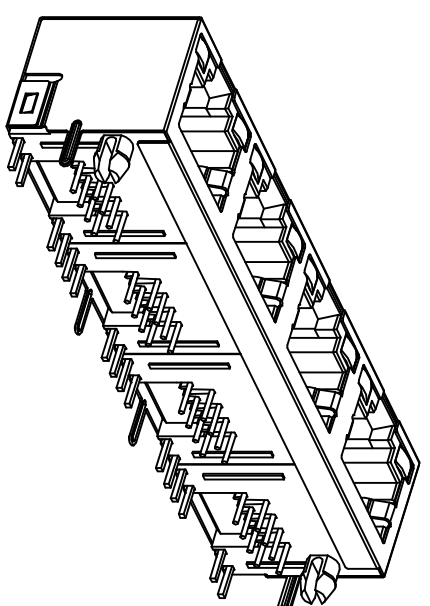

PCB LAYOUT(TOP VIEW)
RECOMMENDED

网络插座外形图



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

序号	名称	材料	数量	镀层/颜色	备注
6	外壳	BS2	1	NI	
5	LED灯	树脂/FE	8	NI/AG	
4	插针	PHOSPHOR BRONZE	32	FU*	
3	中分体	PA46	2	BLACK	
2	右分体	PA46	1	BLACK	
1	左分体	PA46	1	BLACK	

图:	日期:
审:	日期:
核:	日期:

一般公差	公差	公差	公差
30°~	±0.25	10~30	±0.20
~10	±0.15	角度:	±2°
版本:	型号:	图号:	图号:
1 of 1	563114-8Y602010AB30 (RC00543)	RJ45	
单位:mm	比例:1:1	纸张:A4	

必 须 填 写 下 列 图 纸 中 的 项 目

版次	变更履历	变更单号	绘制日期	核准日期
A/0	新出版发行			
1	2	3		

该图面供温州瑞川电子有限公司内部使用,不得私自复印