


General Specification
Current Rating:1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Biting and Limiting Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermo-Plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper

Please refer to the customer drawing when customer has specified

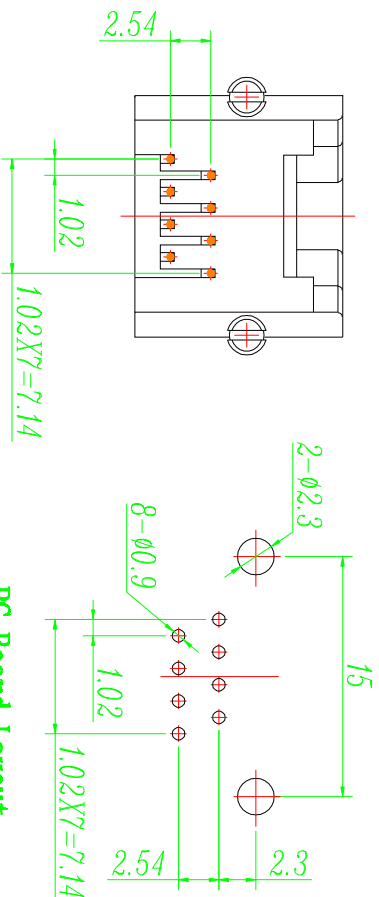

PC Board Layout Top View

2	插针	PHOSPHOR BRONZE	8	FU ^o	
1	塑座	PBT	1	GREY	
序号	名称	材料	数量	镀层颜色	备注

网络插座外形图

绘图:	吴素飞	日期:	2022.4.7
-----	-----	-----	----------

审核:	日期:
司清德	

核 准:	日期:
刘学文	

温州瑞川电子有限公司 WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD. 一般公差 品名: ROH-55-A(无耳)

料号:	55A-80000010PJ32 (WR40041)	
规格:	PI45	图号:
>10~30	±0.35	
~10	±0.25	

角度:	±5°	版本:	单位: mm	比例: 1:1	纸张: A4	
页面:	1 of 1					