
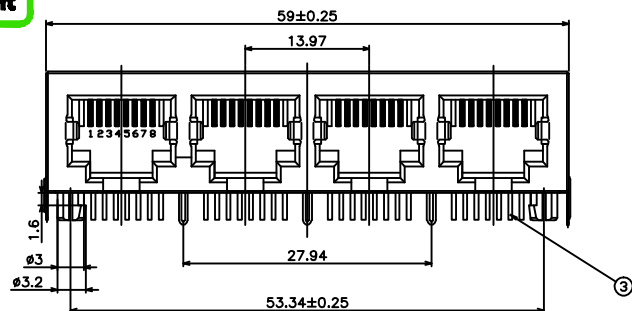
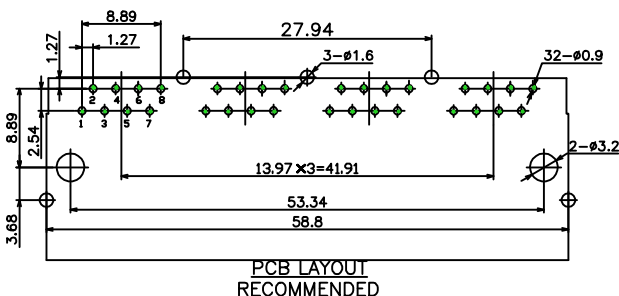


General Specification
Current Rating: 1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating: 120V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance: <30mΩ
Insulation Resistance: >500MΩ
Dielectric Strength: 500V AC/(50HZ)/Min
Mating And unmating Force: 3~20N
Durability: 700 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

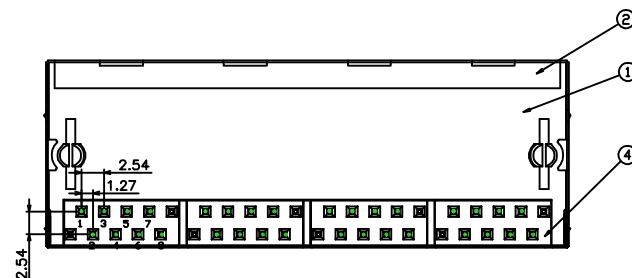

4	后盖	PA46	4	BLACK	
3	插针	PHOSPHOR BRONZE	32	FU	
2	外壳	H62	1	NI	
1	插座	PA46	1	BLACK	
序号	名称	材料	数量	镀层/颜色	备注

网络插座外形图

温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

一般公差	品名	RCH-59-01-14(无灯无弹前脚3.68)			
30~	±0.25	料号	590114-80004310AB31 (RC00237)		
10~30	±0.20	型号	RJ45	图号	
~10	±0.15	版本	单位:mm	比例: 1:1	纸张: A4
角度:	±2°	页码:	1 of 1		

版次	变更履历	变更单号	绘制	日期
A/0	新出版发行			

绘图:	日期:
审核:	日期:
核准:	日期: