

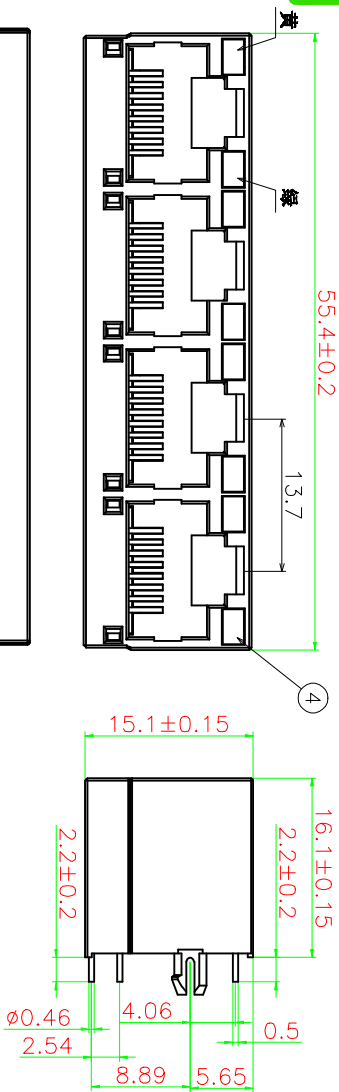


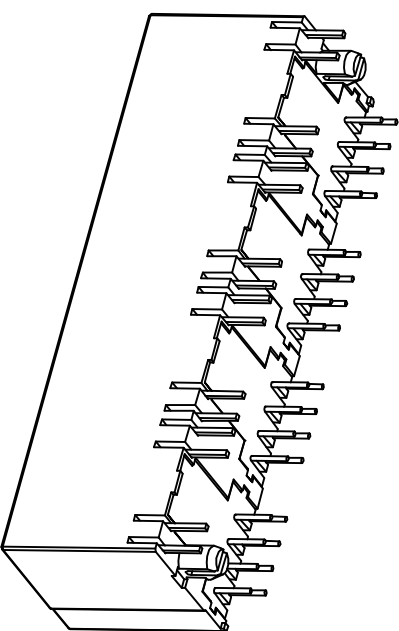

General Specification:
Current Rating: 1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating: 120V AC /Contact, 2.0 volts DC for LED signals
Operating Environment:
Standard Temperature:
Industrial Temperature:
Humidity: 20~70%
Contact Resistance: $\leq 50\text{m}\Omega$
Insulation Resistance: $\geq 500\text{M}\Omega$
Dielectric Strength: 200V AC/50HZ /Min
Testing and Unrating Force: 3~20N
Durability: 750 Cycles Min

Material Specification
Housing: Thermoplastic, UL94V-0
Contact: Alloy Copper
Shield: Alloy Copper

Please refer to the customer drawing when customer has specified

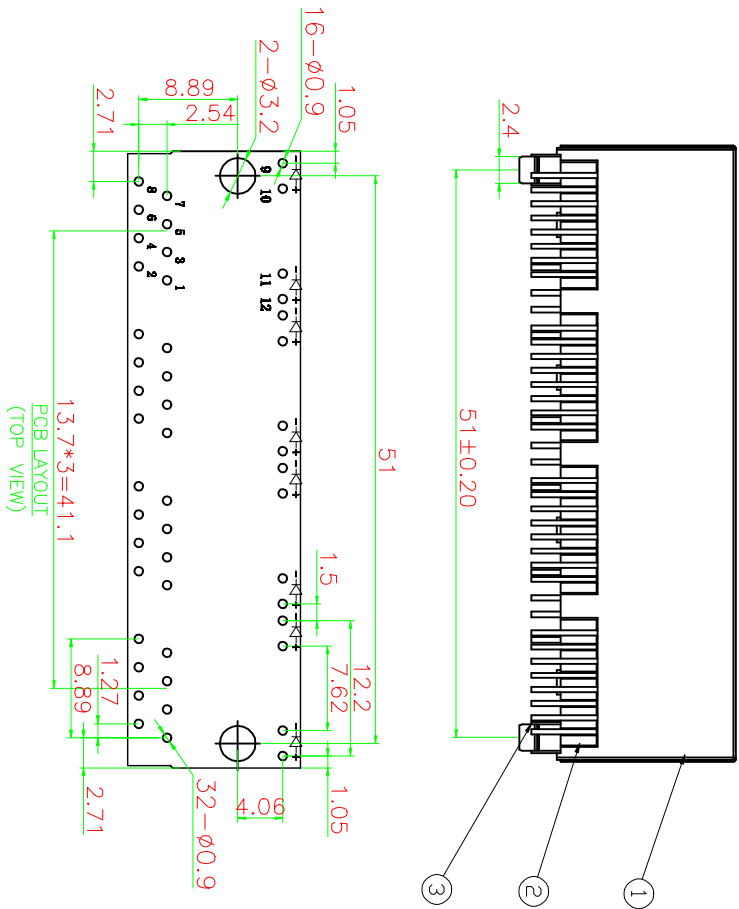

温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

4	LED	树脂/Pe	8	NI	
3	插针	PHOSPHOR BRONZE	32	FR*	
2	后盖	PA46	4	BLACK	
1	底座	PA46	1	BLACK	
序号	名称	材料	数量	键层/颜色	备注

审核:	日期:	2022.4.8	公差	±0.25	品名:	RGH-52-42-14(带灯全题)	黄绿 负正
审核:	日期:	2022.4.8	公差	±0.25	料号:	524214-8Y620010AB22	(PR02327)
审核:	日期:	2022.4.8	公差	±0.15	型号:	RJ45	图号:
审核:	日期:	2022.4.8	公差	±2°	单位:mm	比例: 1:1	纸张: A4