

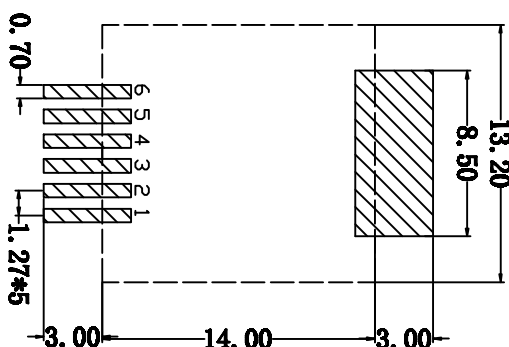
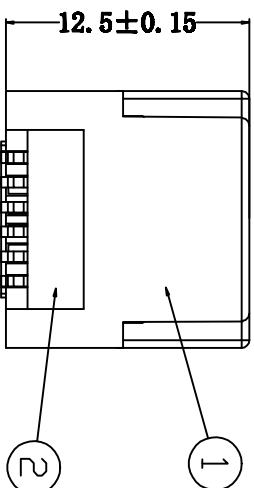


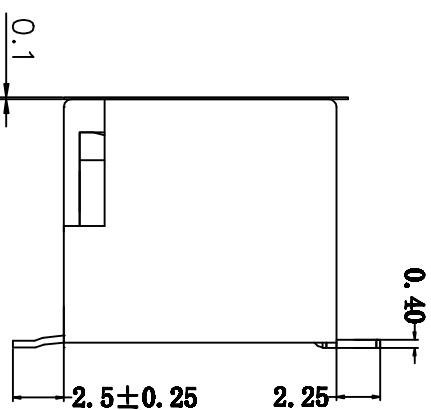

General Specification
Current Rating:1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Mating And Unmating Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

网络插座外形图

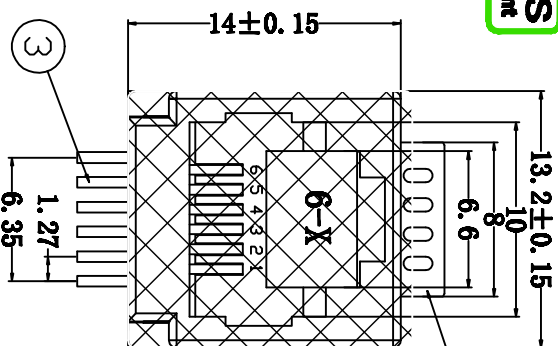

温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO.,LTD.

序号	名称	材料	数量	镀层/颜色	备注
4	定位片	H82	1	CT	
3	插针	PHOSPHOR BRONZE	6	11U"	
2	后盖	LCF	1	BLACK	
1	插座	LCF	1	BLACK	

绘图:	陈飞	日期:	2023.6.8
审核:	陈飞	日期:	
批准:	陈飞	日期:	

品名:	KCF-SF3511 TP 6P6C 全塑
料号:	SF3511TP-60000011IB25 (WR02006)
型号:	RJ11
图号:	

角度:	±5°
角度:	±5°

单位:mm	比例:1:1	纸张:A4
-------	--------	-------

版本

变更履历

变更单号

绘制

日期

审核

批准

日期

页码

1 of 1

版本

图号

图号

图号

图号

图号

1

2

3

该

图

面

供

温州

瑞

川

电

子

有

限

公

司

内

部

使

用

不

得

私

自

复

印