

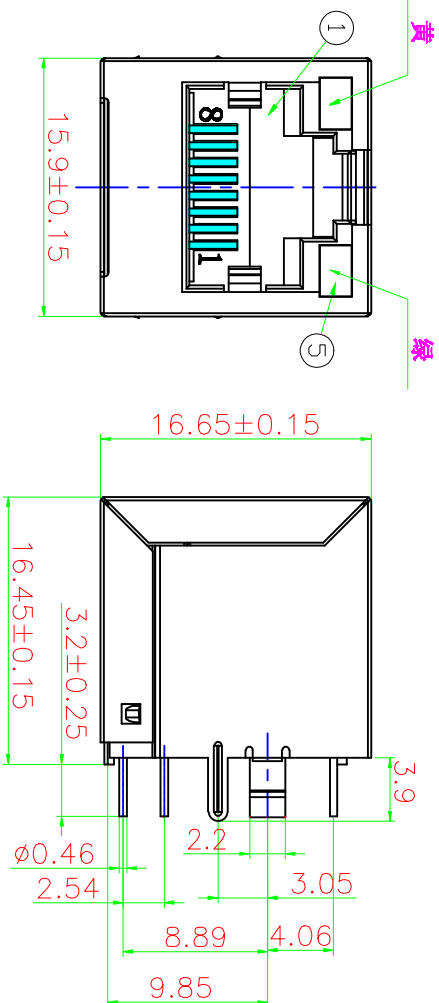


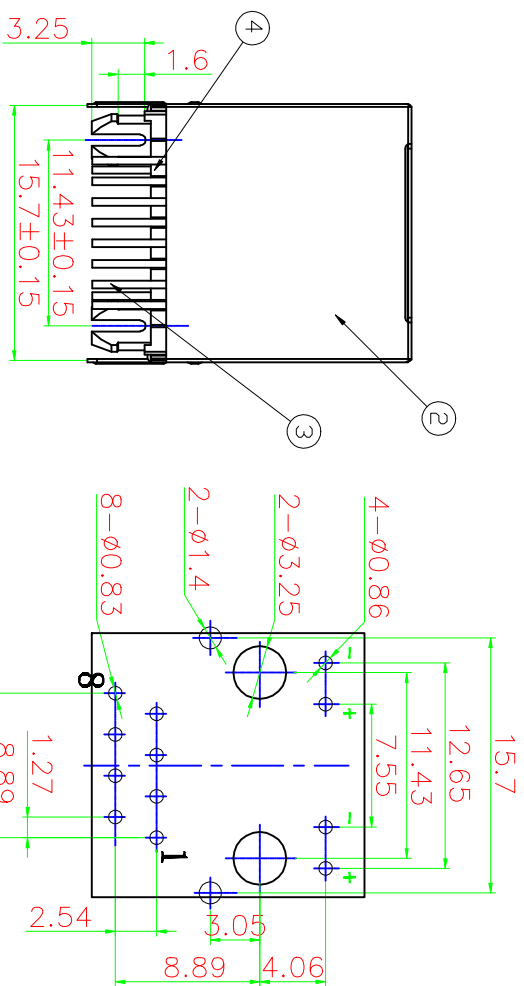

General Specification
Current Rating: 1.5A DC /Contact, 20A DC for LED signals
Voltage Rating: 125V AC /Contact, 240 volts DC for LED signals
Operating Environment
Standard Temperature: -20°C~+70°C
Industrial Temperature: -40°C~+65°C
Humidity: 20~70%
Contact Resistance: $\leq 30m\Omega$
Insulation Resistance: $\geq 500M\Omega$
Dielectric Strength: 500V AC/(50HZ)/Min
Mating and Unmating Force: 3~20N
Durability: 750 Cycles Min

Material Specification
Housing: Thermo-plastic, UL94V-0.
Contact: Alloy Copper
Shield: Alloy Copper

Please refer to the customer drawing when customer has specified

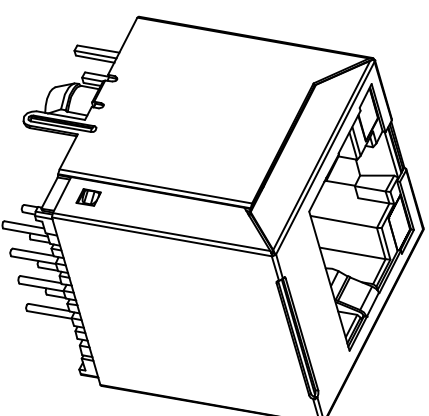

温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

序号	名称	材料	数量	键层/颜色	备注
5	LED灯	树脂/PE	2	NI/AG	
4	后盖	PA66	1	BLACK	
3	插针	PHOSPHOR BRONZE	8	FUT	
2	外壳	H62	1	NI	
1	塑座	PA66	1	BLACK	

				绘图:	吴鹏飞	日期:	2022.4.6	一般公差		品名:		RCH-52-42(带灯后脚3.05) 负正黄绿			
				审核:	王清瑞	日期:		30~	±0.05	10~30	±0.30	料号:	5242-8T(G17010AB32 (WR00001))		
A/0	新出版发行			核准:	朱华生	日期:		~10	±0.15	±0.10	型号:	RJ45	图号:		
变更履历	变更单号	绘制	日期	核准	日期			角度:	±2°	1 of 1	版本:	单位:mm	比例: 1:1	纸张: A4	