
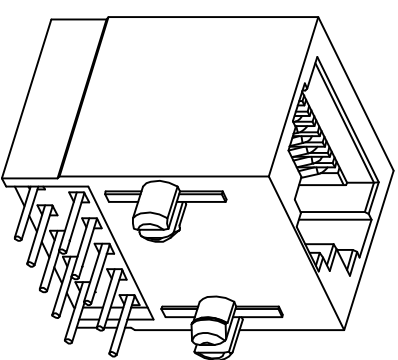
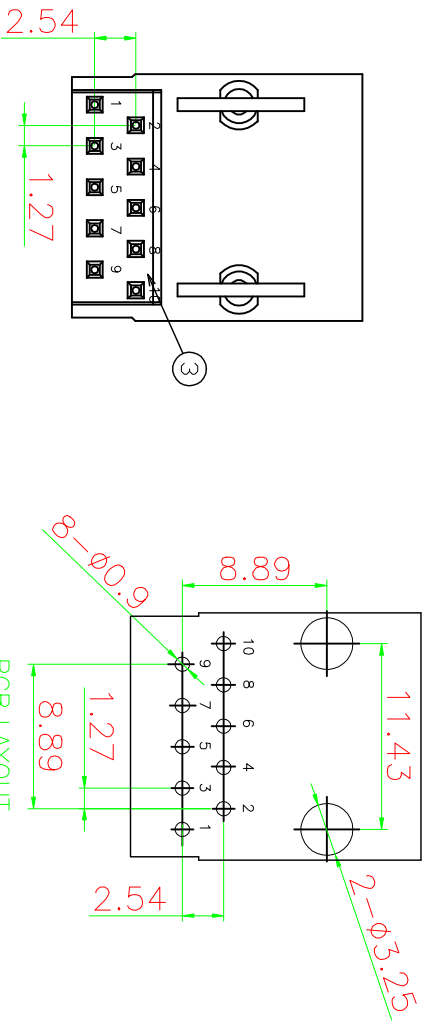
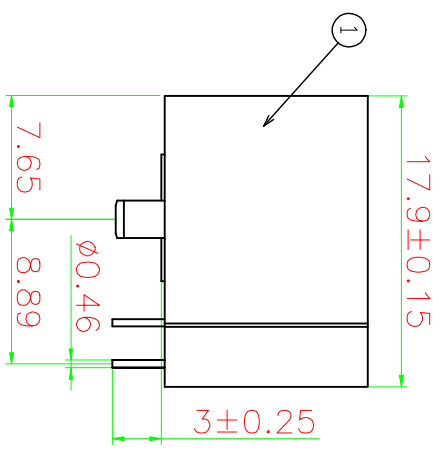


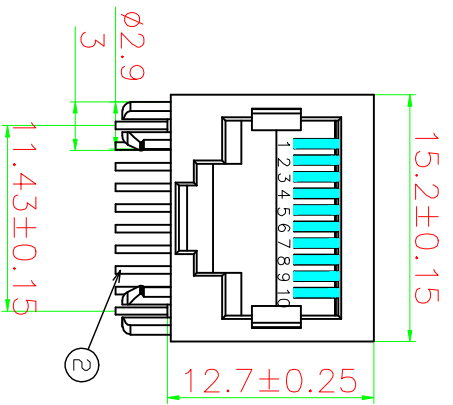

General Specification
Current Rating: 1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance: ≤30mΩ
Insulation Resistance: ≥500MΩ
Dielectric Strength: 500V AC/(50HZ)/Min
Mating And Unmating Force: 3~20N
Durability: 750 Cycles Min

Material Specification
Housing :Thermoplastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper

Please refer to the customer drawing when customer has specified

网络插座外形图



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

绘图:	吴鹏飞	日期:	2022.4.11
审核:	陈伟	日期:	
批准:	陈伟	日期:	

一般公差	公差	品名	RCJ-56-04(全塑10P10C)
30~	±0.25	料号	5604-F0000010AB30 (RC01037)
10~30	±0.30	型号	RJ45
~10	±0.15	图号	
角度:	±2°	版本	
页面:	1 of 1	单位:mm	比例: 1:1
		纸张: A4	

版本号	变更履历	变更单号	绘制日期	审核日期	批准日期
A/0	新出版发行				