
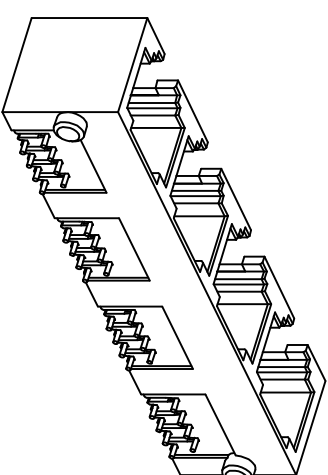
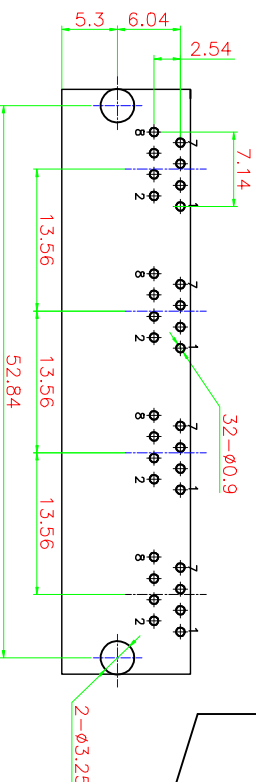
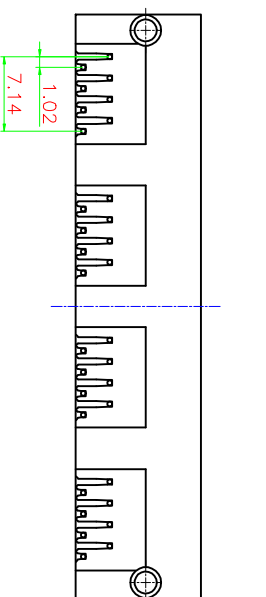
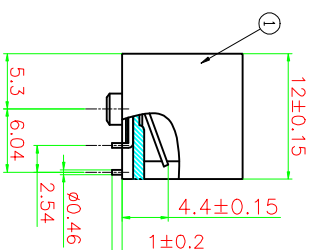
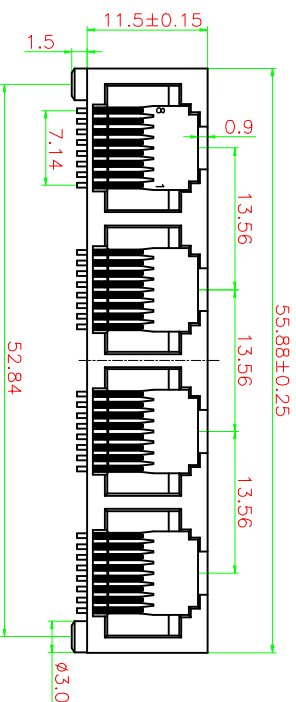


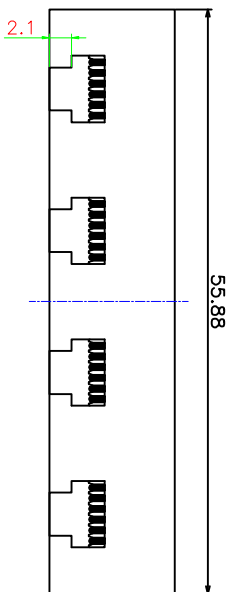

General Specification
Current Rating: 1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20°C~+70°C
Industrial Temperature: -40°C~+85°C
Humidity: 20~70%
Contact Resistance: ≤30mΩ
Insulation Resistance: ≥500MΩ
Dielectric Strength: 500V AC /50HZ /Min
Testing And Unmating Force: 3~20N
Durability: 750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper

Please refer to the customer drawing when customer has specified

网络插座外形图



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

2	插针	PROSETR BRONZE	32	FU"	
1	塑座	PAGT	1	YELLOW	
序号	名称	材料	数量	镀层/颜色	备注

图号	日期	2022.5.16
审核	日期	
核准	日期	

品名	RC4-5366TKH-14(114C防呆型)
料号	5366TKH14-800000107Y10 (WR01458)
型号	RJ45

角度	±2°
版本	1 of 1
单位:mm	比例: 1:1

纸张	A4
图号	

图面	供温州瑞川电子有限公司内部使用,不得私自复印
----	------------------------

图号	日期	2021.8.17
审核	日期	
核准	日期	

图号	日期	2022.5.16
审核	日期	
核准	日期	

图号	日期	2022.5.16
审核	日期	
核准	日期	

图号	日期	2022.5.16
审核	日期	
核准	日期	