

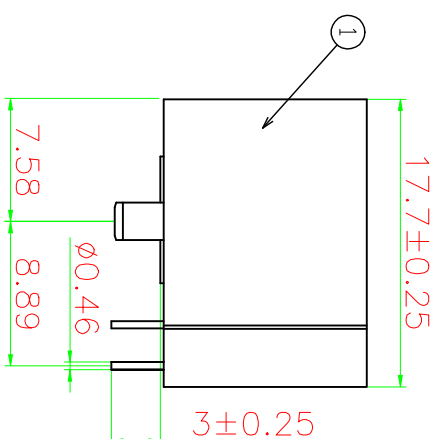


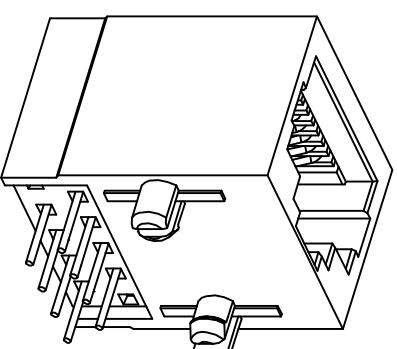

General Specification
Current Rating:1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50Hz)/Min
Rating And Unrating Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper

Please refer to the customer drawing when customer has specified

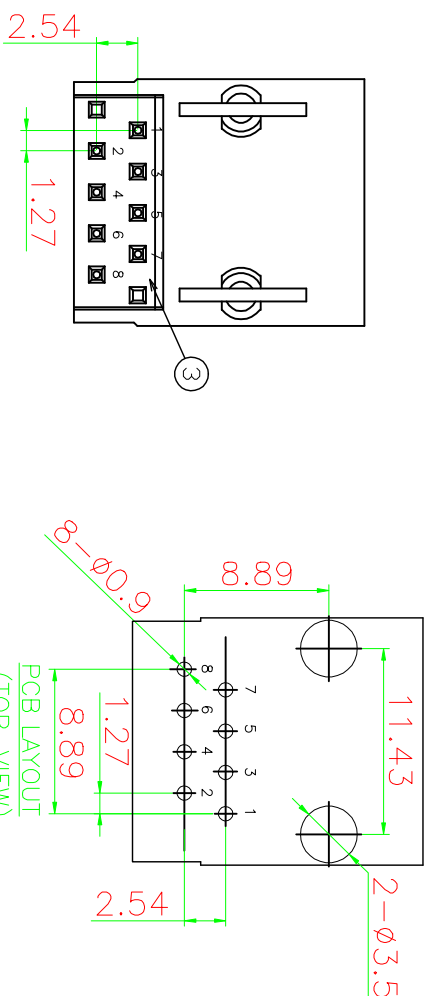

网络插座外形图

3	后盖	PA46	1	BLACK	
2	插针	PHOSPHOR BRONZE	8	PU*	
1	塑座	PA46	1	BLACK	
序号	名称	材料	数量	键层/颜色	备注



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

绘图日期: 2023.2.24

母			
其			
子			
口			
語			

申 报 人:	日期:
--------	-----

日期:	2014年	月	日
推:	李	李	李
校:	李	李	李

一般公差	品名:	RGH-56-04(全塑10P8C)
1.0mm		

30~	±0.50	料 号: 5604-80000010AB30 (WRO2863)
10~30	±0.20	

~10	±0.15	型 号:	RJ45	图 号:
~10	±0.15	型 号:	RJ45	图 号:

图例:	比例: 1:1	纸张: A4	
图例:	比例: 1:1	纸张: A4	