
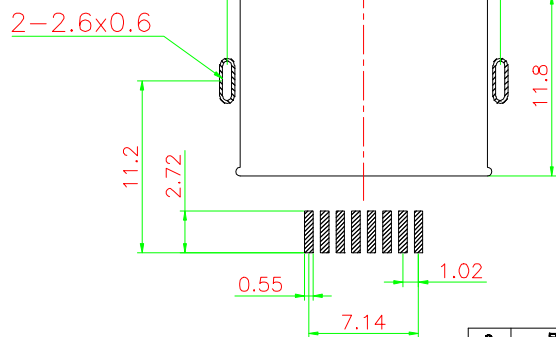
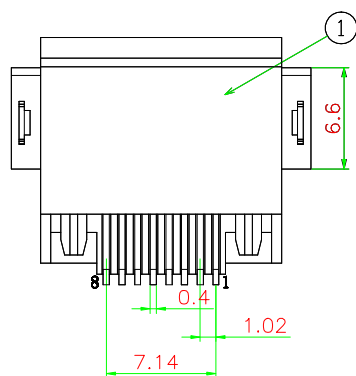
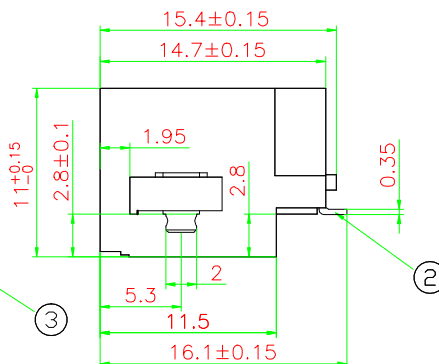
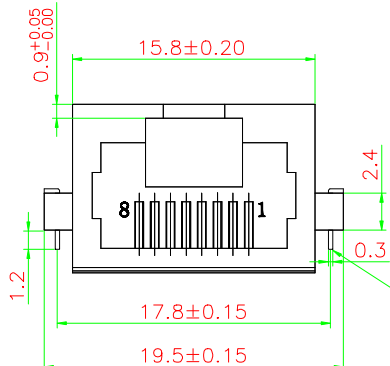


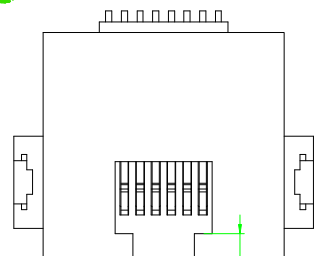

PCB LAYOUT
RECOMMENDED

General Specification
Current Rating:1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Mating And Unmating Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

3	固定脚	Fe	2	Sn	
2	插针	PHOSPHOR BRONZE	8	Au ⁺ 1U ⁺	
1	塑座	PA9T	1	BLACK	
序号	名称	材料	数量	镀层/颜色	备注

温州瑞川电子有限公司 WEN ZHOU RUI CHUAN ELECTRONIC CO.,LTD.					
一般公差		品名:	RCH-XSP-31TPG(全塑)		
90~	±0.25	料号:	XSP31TPG-80000011TB14 (WR44145)		
10~30	±0.20	型号:	RJ45	图号:	
~10	±0.15	版本:	单位:mm	比例: 1:1	纸张: A4
角度:	±2°				
页面:	1 of 1				

网络插座外形图

绘图:		日期:	
审核:		日期:	
核准:		日期:	

版次

变更履历

变更单号

绘制

日期

核准:

日期:

1

2

3

该图面供温州瑞川电子有限公司内部使用, 不得私自复印