

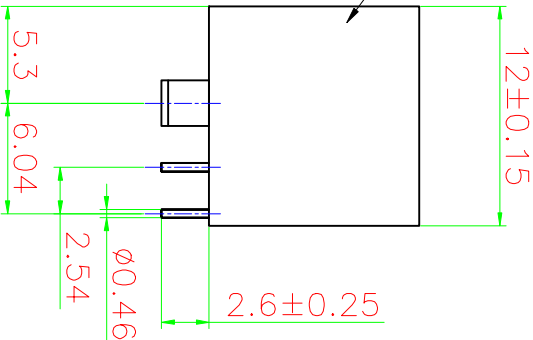
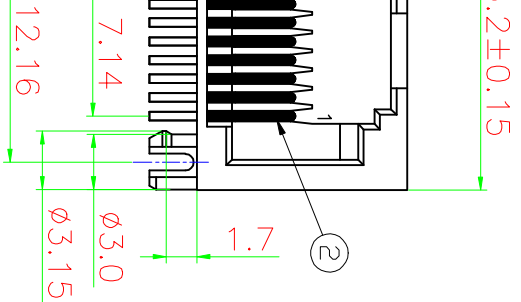


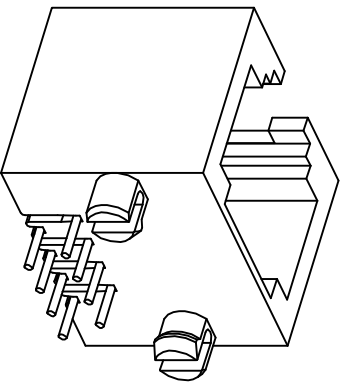

General Specification
Current Rating: 1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20°C~+70°C
Industrial Temperature: -40°C~+85°C
Humidity: 20~70%
Contact Resistance: $\leq 30m\Omega$
Insulation Resistance: $\geq 500M\Omega$
Dielectric Strength: 500V AC / (50HZ) /Min
Making And Breaking Force: 3~20N
Durability: 750 Cycles Min

Material Specification
Housing : Thermo-plastic, UL94V-0.
Contact : Alloy Copper
Shield : Alloy Copper

Please refer to the customer drawing when customer has specified

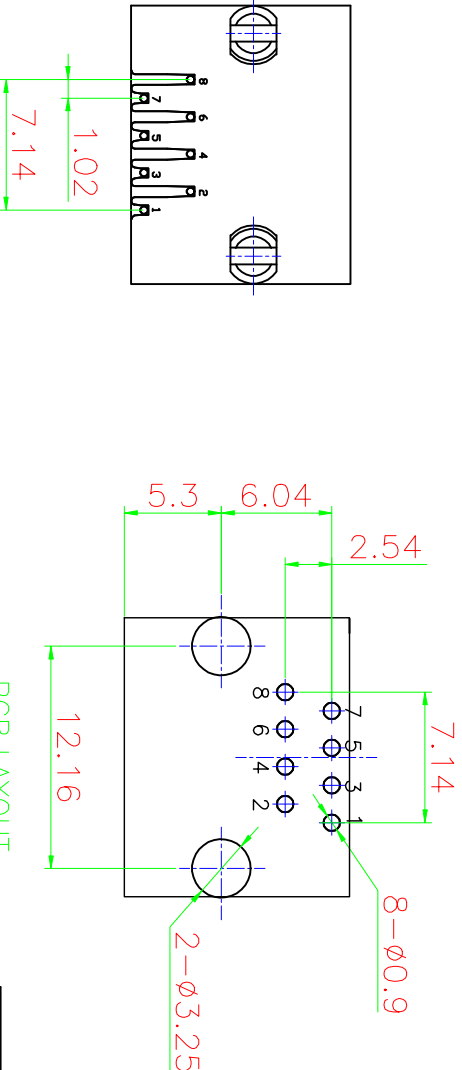

网络插座外形图

2	插座	PHOSPHOR BRONZE	8	FU"	
1	塑座	PA46/PBT	1	BLACK	
序号	名称	材料	数量	镀层/颜色	备注



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

一般公差		品名		RCF-5366 黑座	
30~	±0.25	料号	5366-80000010PB26 (RC01432)		
10~30	±0.20	型号	RJ45		
~10	±0.15				
角度	±2°				
面	1 of 1	版本			
		单位mm	比例 1:1	纸张 A4	