
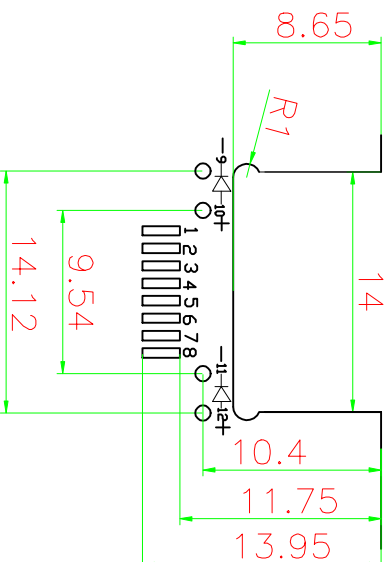
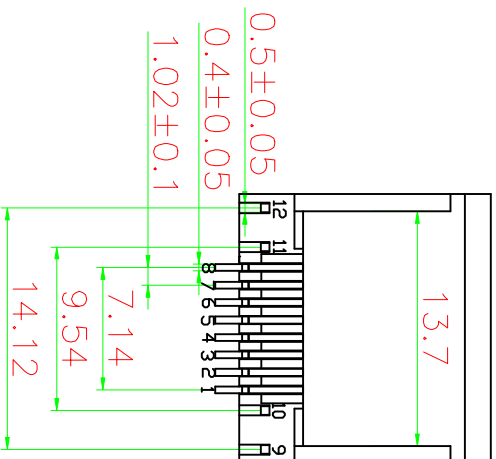
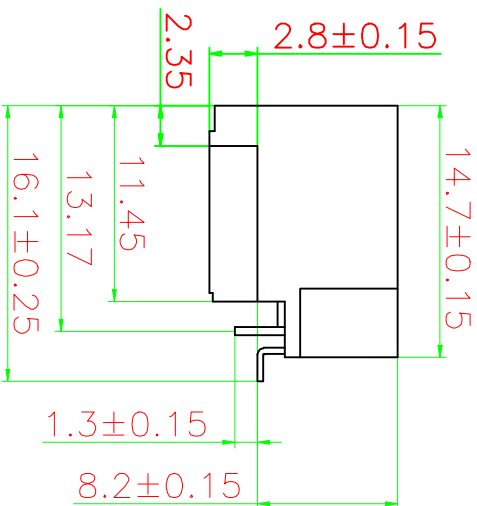


General Specification
Current Rating: 1.6A DC /Contact, 20mA DC for LED signals
Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance: $\leq 30m\Omega$
Insulation Resistance: $\geq 500M\Omega$
Dielectric Strength: 500V AC/(50HZ)/Min
Mating And Unmating Force: 3~20N
Durability: 750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper

Please refer to the customer drawing when customer has specified

网络插座外形图

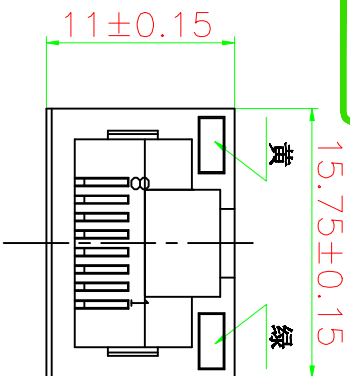

温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

序号	名称	材料	数量	镀层/颜色	备注
3	LED灯	树脂/FE	2	NI/AG	
2	插针	PHOSPHOR BRONZE	8	1U"	
1	塑座	LCP	1	BLACK	

图: 吴豪飞 日期: 20230108

审核: 日期:

批准: 日期:

一般公差	品名	料号	型号	图号
30~ 10~30 ~10	RCR-SP-32-TC-2.8(全塑带灯)	SP32TC2.8-8YG10001LB13 (RC01818)	RJ45	
角度: ±2°	版本	单位:mm	比例: 1:1	纸张: A4
页面: 1 of 1				