

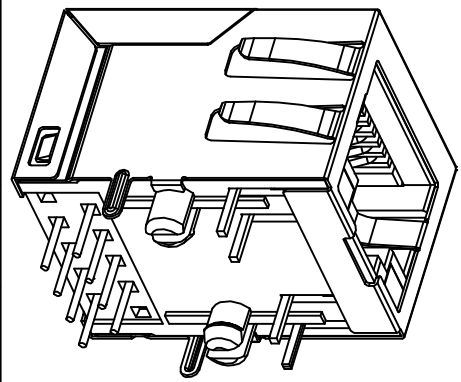
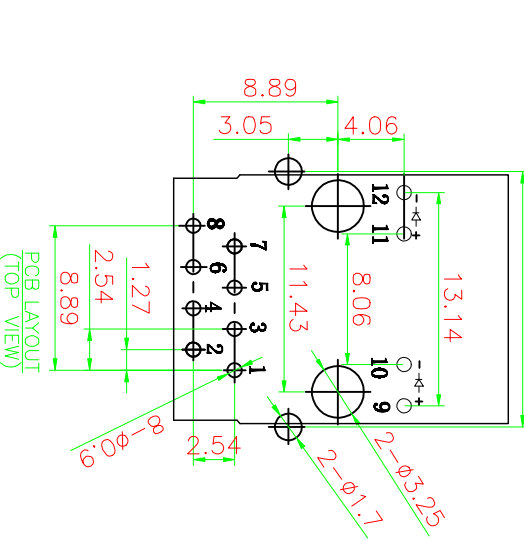
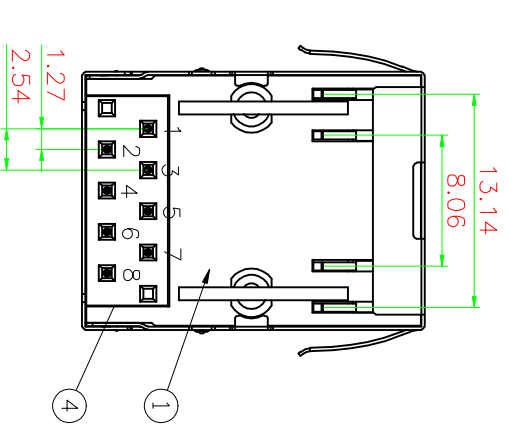


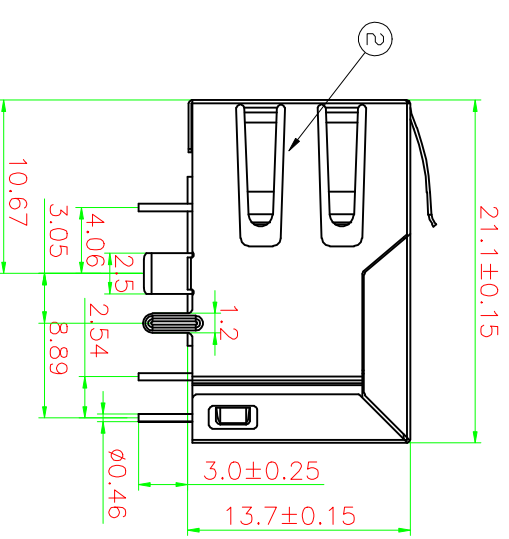

General Specification
Current Rating:1.6A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Bending And Unbending Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermoplastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customers drawing when customer has specified

网络插座外形图

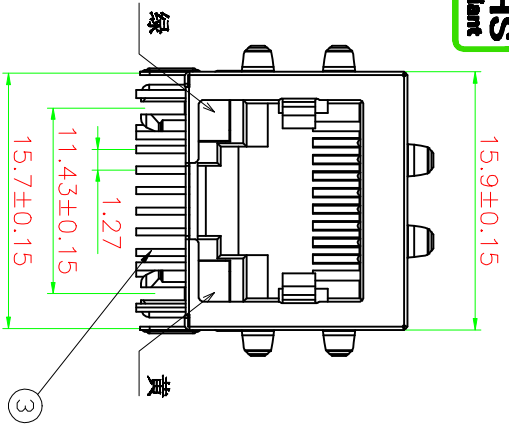

温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

序号	名称	材料	数量	镀层/颜色	备注
5	LED灯	树脂/PE	2	NT/AG	
4	后盖	PA46	1	BLACK	
3	插针	PHOSPHOR BRONZE	8	FU*	
2	外壳	HS2	1	NT	
1	底座	PA46	1	BLACK	

绘图:	吴鹏飞	日期:	2022.7.21
审核:	陈德	日期:	
批准:	陈德	日期:	

一般公差	公差	品名	RCR-59-01(带灯带弹后脚3.05)
30~	±0.25	料号	5901-8G107410AB30 (RCR0247)
10~30	±0.30	型号	RJ45
~10	±0.15	图号	
角度:	±2°	版本	
页面:	1 of 1	单位:mm	比例:1:1
		纸张:A4	

版本

变更履历

变更单号

绘制日期

审核日期

批准日期

日期

日期

日期

日期

日期

日期

日期