
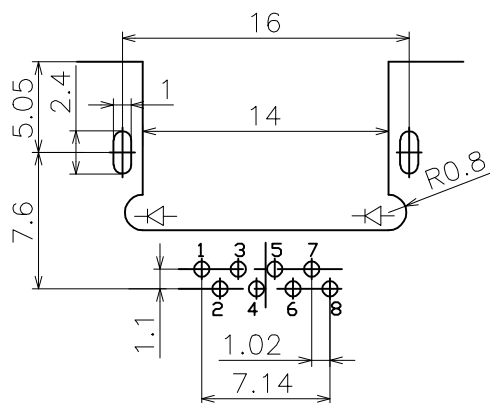
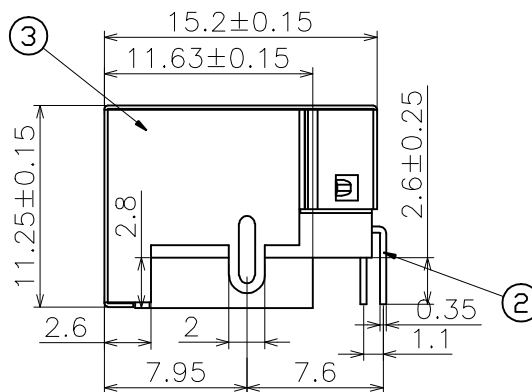
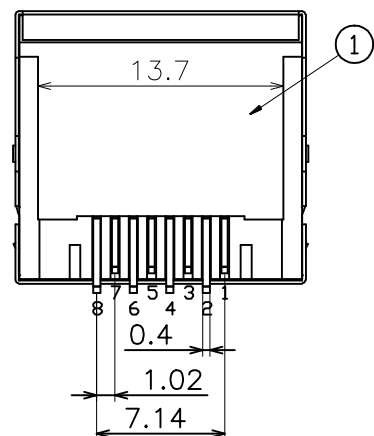


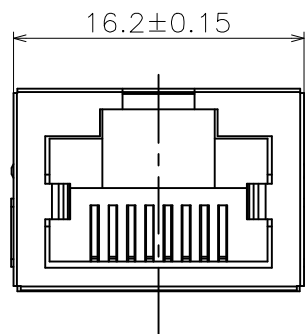


PCB LAYOUT
RECOMMENDED

General Specification

Current Rating: 1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance: ≤30mΩ
Insulation Resistance: ≥500MΩ
Dielectric Strength: 500V AC/(50HZ)/Min
Mating And unmating Force: 3~20N
Durability: 750 Cycles Min

Material Specification

Housing : Thermo-plastic, UL94V-0.
Contact : Alloy Copper
Shield : Alloy Copper
Please refer to the customer drawing when customer has specified

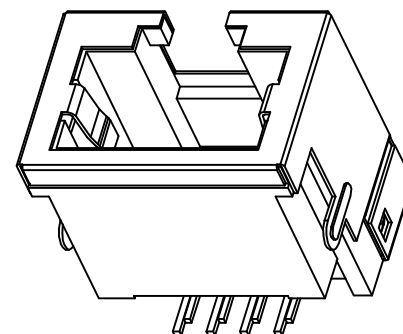

X-4.2/2.8

3	外壳	H62	1	NI	
2	插针	PHOSPHOR BRONZE	8	10°	
1	插座	LCP	1	BLACK	
序号	名称	材料	数量	镀层/颜色	备注



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

一般公差	品名:	RJH-SP-32 (无灯无弹)			
90~	±0.25	料号:	SP32-80002001LB26 (WR01824)		
10~30	±0.20	型号:	RJ45	图号:	
~10	±0.16	版本:	单位:mm	比例: 1:1	纸张: A4
角度:	±2°				
页面:	1 of 1				

网络插座外形图

绘图: 吴飞 日期: 2022.12.26
审核: 日期:
核准: 日期:

A/0

新出版发行

版次

变更履历

变更单号

绘制

日期

核准

日期

该图面供温州瑞川电子有限公司内部使用, 不得私自复印