



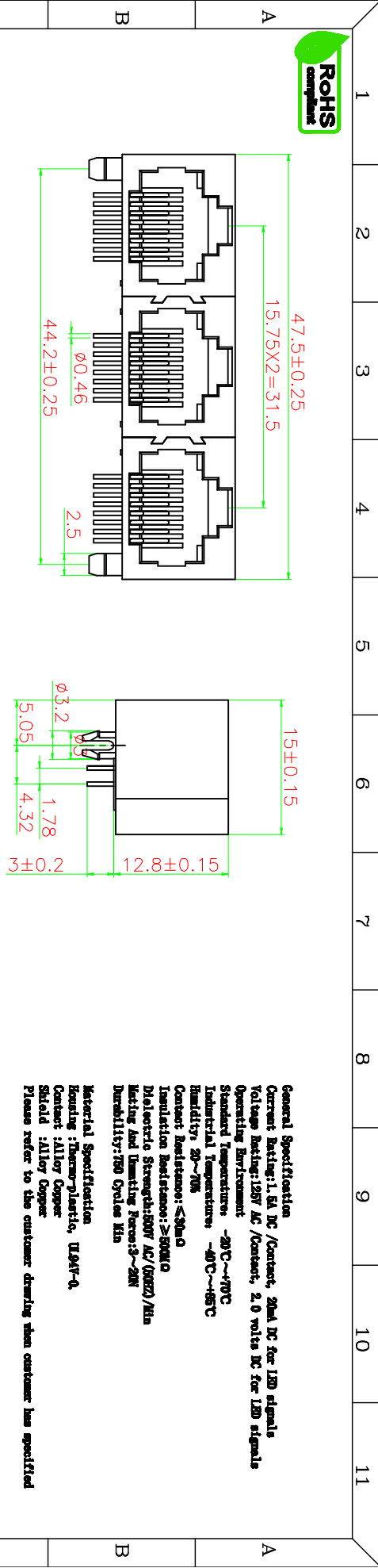

General Specification
Current Rating:1.6A DC /Contact, 20mA DC for LED signals
Voltage Rating:150V AC /Contact, 2.0 volts DC for LED signals
Operating Environment:
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance: ≤30mΩ
Insulation Resistance: ≥500MΩ
Dielectric Strength:1500V AC /500Z/Min
Withstanding Voltage:3~20KV
Durability:700 Cycles Min

Material Specification
Housing :Thermoplastic, UL94V-0,
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

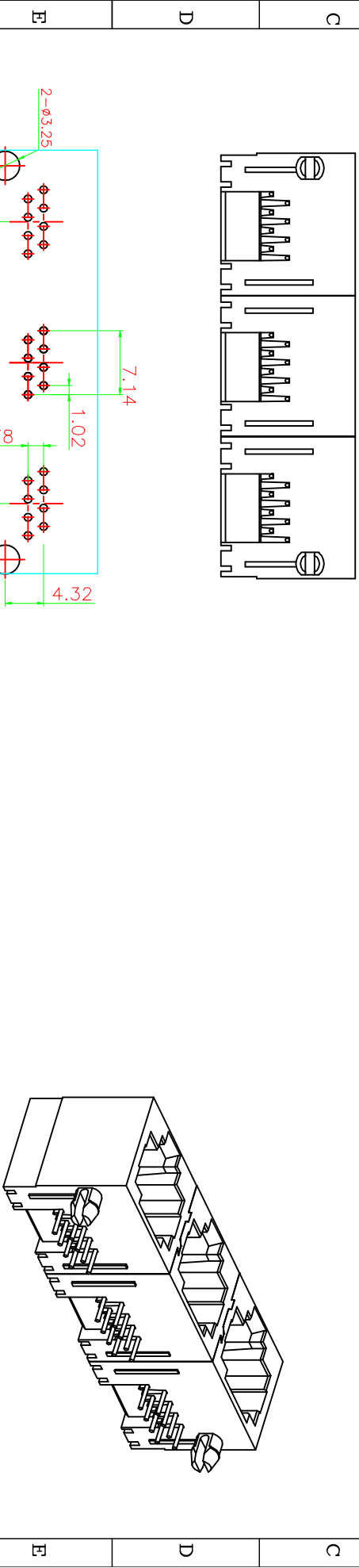

PCB LAYOUT
RECOMMENDED

网络插座外形图



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

序号	名称	材料	数量	镀层/颜色	备注
4	插针	PHOSPHOR BRONZE	32	RU"	
3	中分体	PA46	2	BLACK	
2	右分体	PA46	1	BLACK	
1	左分体	PA46	1	BLACK	

一般公差
30~ ±0.25
10~30 ±0.20
~10 ±0.15
角度: ±2°
版本: 1 of 1
比例: 1:1
纸张: A4

品名: RCH-56-31-13 (无灯全塑)
料号: 563113-80000010AB30 (RC00169)
型号: RJ45
图号:

图:	日期:	审核:	日期:	日期:
审核:	日期:	日期:	日期:	日期:
版本:	变更履历	变更单号	绘制	日期