


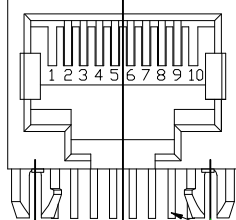


15.2±0.15



11.43±0.15

17.9±0.15

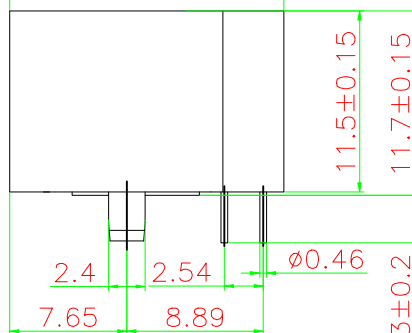

11.5±0.15

11.7±0.15


2.4

2.54

Ø0.46

7.65

8.89

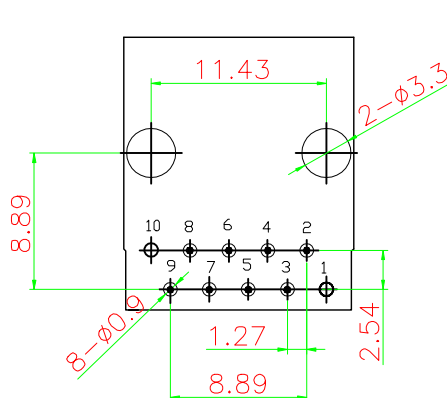

PCB LAYOUT
(TOP VIEW)

General Specification

Current Rating:1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Mating And unmating Force:3~20N
Durability:750 Cycles Min

Material Specification

Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

3	后盖	PA46	1	BLACK	
2	插针	PHOSPHOR BRONZE	8	FU	
1	插座	PA46	1	YELLOW	
序号	名称	材料	数量	镀层/颜色	备注



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

一般公差		品名:	RJH-56-21(全塑)		
90~	±0.25	料号:	5621-80000010AB33		
10~30	±0.20	型号:	RJ45	图号:	RC01047
~10	±0.16	版本:	单位:mm	比例: 1:1	纸张: A4
角度:	±2°				
页面:	1 of 1				

网络插座外形图

绘图:	日期:
审核:	日期:
核准:	日期:

A/0

新出版发行

版次

变更履历

变更单号

绘制

日期

核准

日期

该图面供温州瑞川电子有限公司内部使用,不得私自复印