

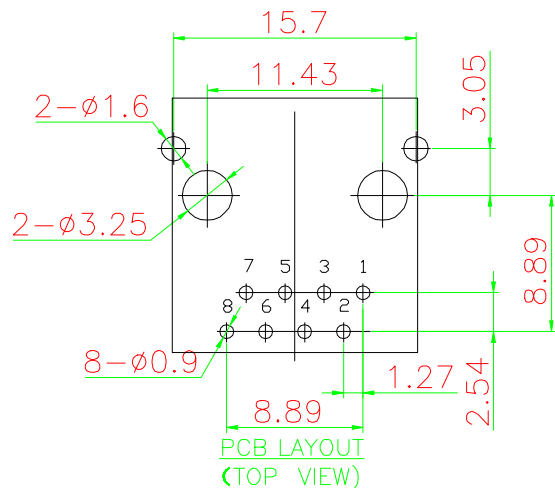
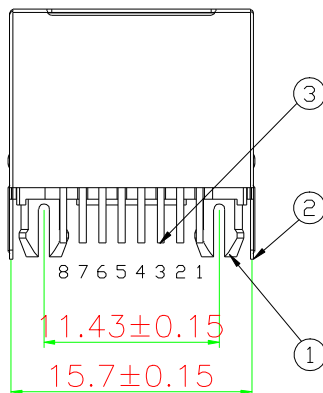
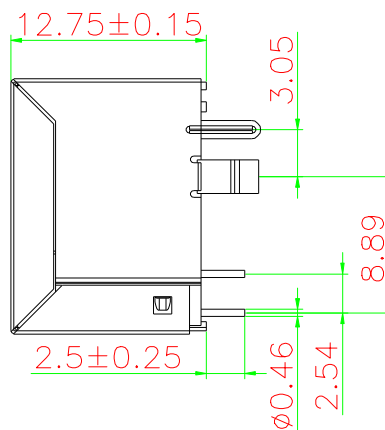


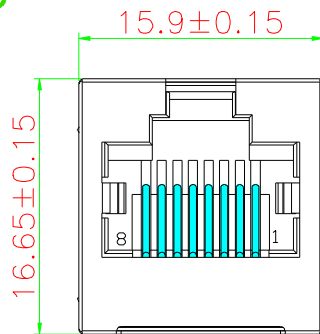

General Specification
Current Rating:1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Mating And Unmating Force:3~20N
Durability:750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

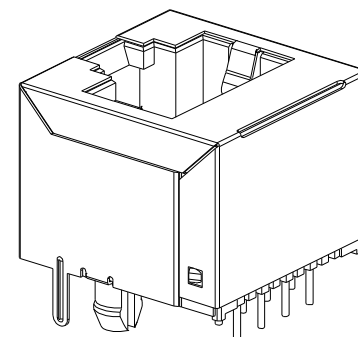

3	插针	PHOSPHOR BRONZE	8	FU"	
2	外壳	H62	1	NI	
1	塑座	PA46	1	BLACK	
序号	名称	材料	数量	镀层/颜色	备注



温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

一般公差	品名:	RCH-52-42-CB(无灯前脚3.05)
90~	料号:	5242CB-80003010AB25 (RC01922)
10~30	型号:	RJ45
~10	图号:	
角度: ±2°	版本:	
页面: 1 of 1	单位: mm	比例: 1:1
	纸张: A4	

网络插座外形图

绘图: 魏飞 日期: 2022.4.8
审核: 陈伟 日期:
核准: 陈伟 日期:

A/0 新出版发行

变更履历

变更单号

绘制

日期

核准

日期

该图面供温州瑞川电子有限公司内部使用, 不得私自复印