
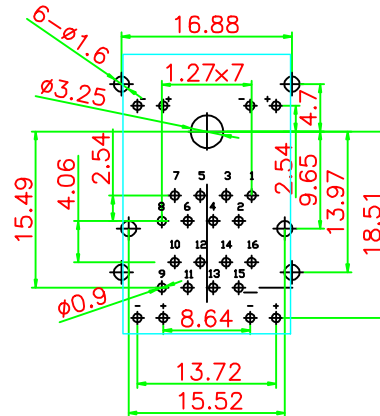
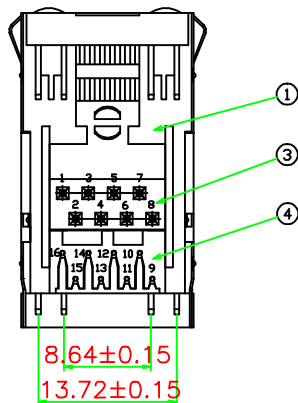
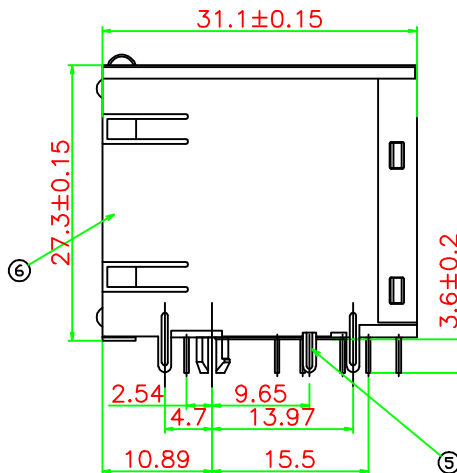


RoHS
compliant

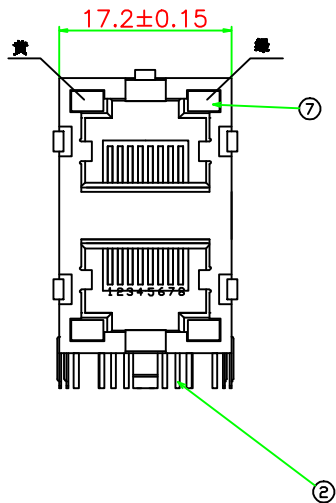

PCB LAYOUT
(TOP VIEW)

General Specification

Current Rating:1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating:125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance:≤30mΩ
Insulation Resistance:≥500MΩ
Dielectric Strength:500V AC/(50HZ)/Min
Mating And unmating Force:3~20N
Durability:750 Cycles Min

Material Specification

Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

7	LED灯	树脂/FE	4	NI/AG	
6	外屏蔽	H62	1	NI	
5	内屏蔽	H62	1	NI	
4	长后盖	PA46	1	BLACK	
3	短后盖	PA46	1	BLACK	
2	插针	PHOSPHOR BRONZE	16	FU ⁺	
1	插座	PA46	1	BLACK	
序号	名称	材料	数量	镀层/颜色	备注

网络插座外形图

绘图: 魏飞 日期: 2022.4.8
审核: 王洪伟 日期:
核准: 李华 日期:

 温州瑞川电子有限公司
WEN ZHOU RUI CHUAN ELECTRONIC CO., LTD.

一般公差
20~ 20 ±0.25
10~20 ±0.20
~10 ±0.15
角度: ±2°
页码: 1 of 1
品名: RCH-59-01-21(带灯带弹)
料号: 590121-8YG00410AB36 (WR00054)
型号: RJ45 图号:
版本: 单位:mm 比例: 1:1 纸张: A4

A/0 新出版发行

版次 变更履历

变更单号

绘制 日期

核准: 日期:

该图面供温州瑞川电子有限公司内部使用, 不得私自复印