

芯数 Pin	额定电流 Rate Current	额定电压 Rate Voltage	耐压 Dielectric Withstanding Voltage
4	4A	250V	1500 V/Min
5	4A	250V	1200 V/Min
8	2A	30V	500 V/Min
12	1A	30V	500 V/Min

3,2±0.1

材料Material

胶芯原料Insulator: PA46, (UL 94V-0)

外壳材料Related Material: Brass

表面涂层Surface Coating: Nickel Plating

针材料Related Material: Male-Brass


Female-Bronze

表面涂层Surface Coating: Overgold 1u

规格参数Planning Parameters

绝缘电阻Insulation Resistance: ≥100MΩ

工作温度Operating Temperature: -40+150°

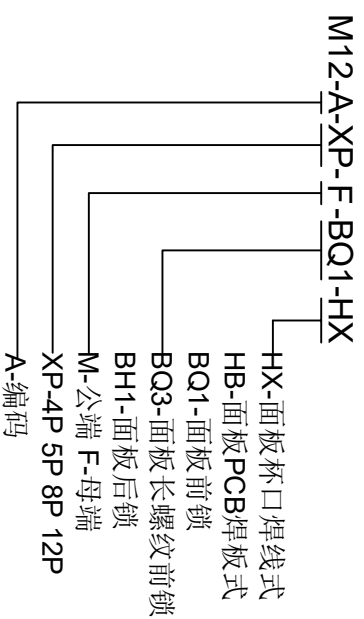

上海洲日电子有限公司

Shanghai Zhouri Electronics CO.,LTD

上海康司玛电子设备进出口有限公司

Shanghai KangSilva Electronic Equipment
Import and export Co.,LTD

tel: 021-51571121
fax: 021-51571120

<http://www.zhouri.net>

产品名称: M12-A-XP-F-BQ1-HX

绘图: MAXIA	日期: 202111027
审核: 张海娜	日期: 20211027
版本号: ZRLCGY2021-10-20-CJ/1	
第三视角:	单位: mm

比例: 图幅: A4 页次 共 01 第 01