

材料Material

胶芯原料Insulator:PA46,(UL 94V-0)

外壳材料Related Material: Brass

表面涂层Surface Coating:Nickel Plating

针材料Related Material: Male-Brass

Female-Bronze


表面涂层Surface Coating:Overgold 1u

规格参数Planning Parameters

绝缘电阻Insulation Resistance:≥100MΩ

工作温度Operating Temperature:-40+150°

M12-A-XP-M-BQ3-HX

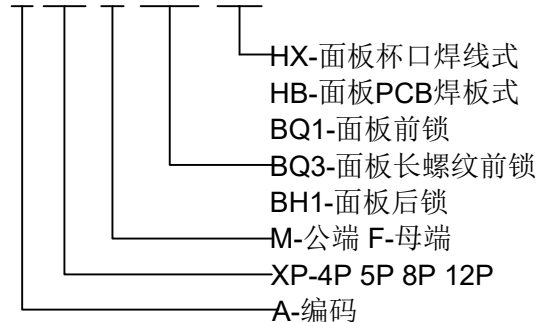

上海洲日电子有限公司

Shanghai Zhouri Electronics CO.,LTD

上海康司玛电子设备进出口有限公司

Shanghai Zhouri Electronics Import And Export Co.,LTD

tel:021-51571121
fax:021-51571120

<http://www.zhourì.net>

产品名称:

M12-A-XP-M-BQ3-HX

绘图:	MAXIA	日期: 20211027
审核:	张海娜	日期: 20211027
版本编号:	ZRLCGY2021-10-20-CJ/2	
第三视角:		单位: mm

芯数 Pin	额定电流 Rate Current	额定电压 Rate Voltage	耐压 Dielectric Withstanding Voltage
4	4A	250V	1500 V/Min
5	4A	250V	1200 V/Min
8	2A	30V	500 V/Min
12	1A	30V	500 V/Min