


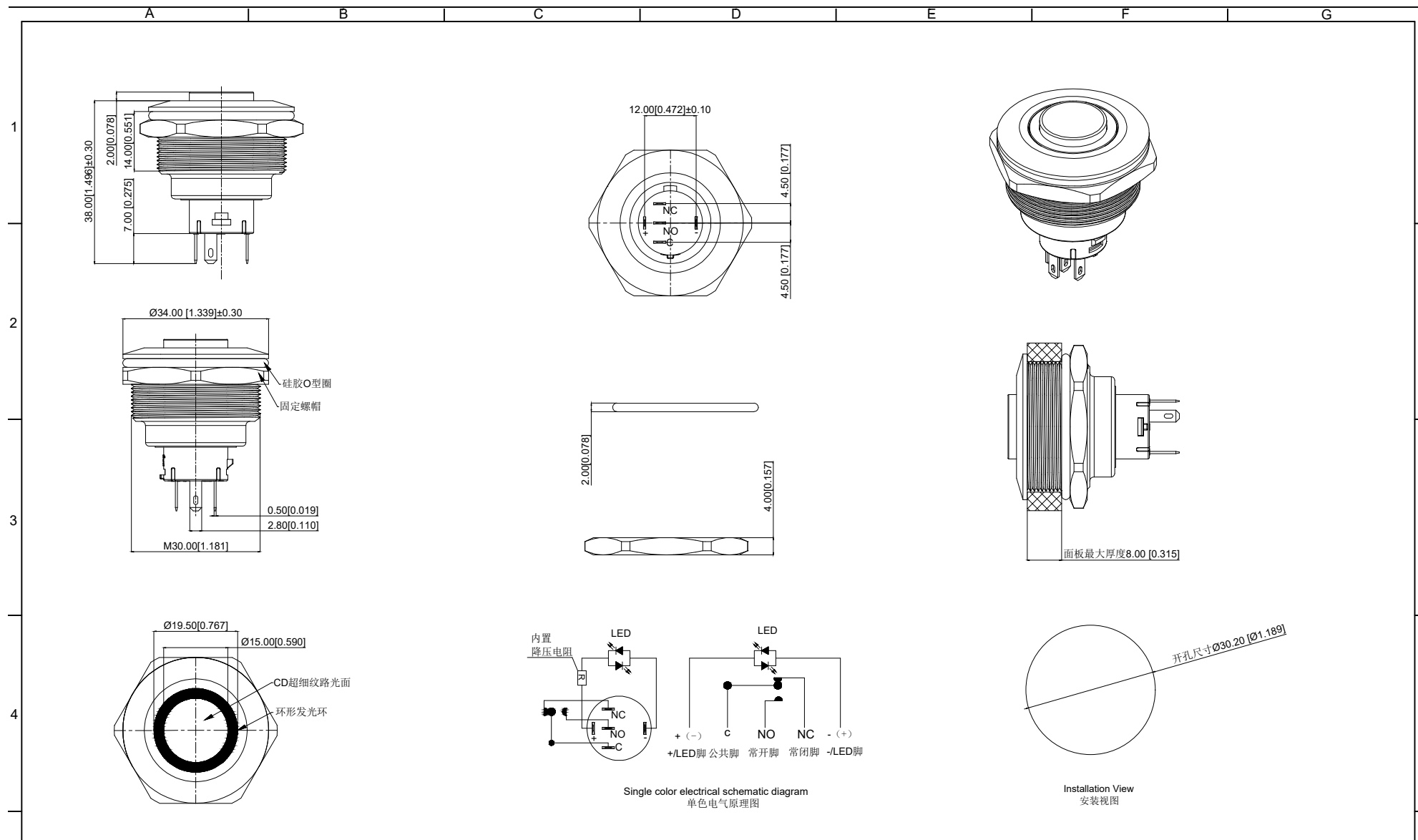

A		B		C		D		E		F		G								
1	性能参数																			
	1. Heating current: Ui: AC250V, Ith: 5A 发热电流: Ui: AC250V, Ith: 5A					13. Working environment temperature: -20 °C~+55 °C 工作环境温度: -20 °C~+55 °C														
	2. Rated current:3A/DC36V 额定电流:3A/DC36V					14. Compression torque: ≤ 2.5N 按压扭力: ≤2.5N														
	3. Power-frequency withstand voltage:2000V1min 工频耐压:2000V1min					15. Electrical life: 100000 cycles 电气寿命: 100000 cycles														
2	4. Insulation resistance:≥1000MΩ 绝缘电阻 :≥1000MΩ					16. mechanical: 500000cycles 机械寿命: 500000cycles														
	5. Contact resistance:≤50mΩ 接触电阻 :≤50mΩ					17. Operation method:Self repeating form 操作方式: 自复式														
	6. Pressing stroke:2.50mm ± 0.10 按压行程:2.50mm ± 0.10					18. LED lamp power consumption: 20m以下 LED灯功耗: 20m以下														
	7. Contact stroke:1.50mm±0.10 接触行程 :1.50mm±0.10					19. LED lamp lifespan: 40000h LED寿命: 40000h														
3	8. welding temperature: 320 °C± 20 °C 焊接温度: 320 °C± 20 °C					20. LED color: Red LED颜色: 红色														
	9. Welding duration: Less than 3 seconds in duration 焊接时长: Less than 3 seconds in duration					21. LED Lamp Voltage: 24V LED灯电压: 24V														
	10. Nut assembly torque:5-14N 螺帽装配力矩:5-14N					22. NO reverse thrust foot torque: ≤30N NO反推脚扭力: ≤30N														
	11. Protection level:IP67 防护等级:IP67																			
4	12. Explosion prevention level: IK10 防暴等级: IK10																			
	连接形式																			

A					B					C					D					E					F					G													
材质参数																																											
1	10		luminous zone 发光区										PC 塑胶					1																									
	9		LEDpin LED引脚										Brass 黄铜					1					Silvering 镀银																				
2	8		Base 底座										PA46					1																									
	7		Pin 引脚										Brass 黄铜					1					gold-plating 镀金																				
3	6		Contact material 接触材质										silver alloy 银合金					1					Silvering 镀银																				
	5		LED Base LED基座										PC 塑胶																														