


Specification Sheet

Part Number: QTTIE0HS

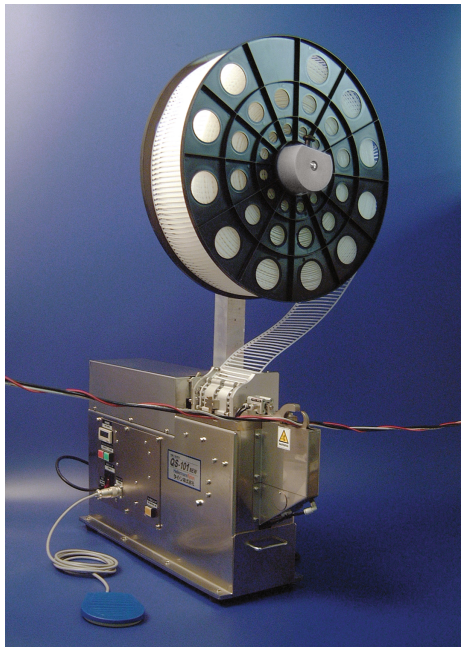

Ties are available in two styles: standard and heat stabilized. Custom colors for Quick Tool ties are also available. Contact HellermannTyton for more information.

Cable Tie for QS101, 18lb Tensile Strength, PA66HSW, Black, 5000 Ties/Reel, 2 Reels/Carton

Article Number	105-00001
----------------	-----------

Type	AZ100
------	-------

Color	Black (BK)
-------	------------

Quantity Per	reel
--------------	------

Product Description	HellermannTyton's Quick Tool is an automatic bench mount system suited for high volume cable tie applications. This air powered tool accommodates a reel of 5000 ties and, like HellermannTyton's other automated systems, can be integrated into further automation as well as fully incorporated into conveyor or assembly line applications. Custom colors for Quick Tool ties are also available.
---------------------	--

Short Description	Cable Tie for QS101, 18lb Tensile Strength, PA66HSW, Black, 5000 Ties/Reel, 2 Reels/Carton
Global Part Name	AZ100-PA66HSUV-BK
Minimum Tensile Strength (Imperial)	18.0
Minimum Tensile Strength (Metric)	80
Length L (Imperial)	3.94
Length L (Metric)	100
Identification Plate Position	none
Reel Diameter (Imperial)	18
Reel Diameter (Metric))	450.00
Reel Width (Imperial)	5.2
Reel Width (Metric)	132
Releasable Closure	No
Variant	bandolier
Width W (Imperial)	0.1
Width W (Metric)	2.5
Bundle Diameter Min (Imperial)	0.03

Bundle Diameter Min (Metric)	0.7
Bundle Diameter Max (Imperial)	0.63
Bundle Diameter Max (Metric)	16.0
Thickness T (Imperial)	0.043
Thickness T (Metric)	1.1
Material	Polyamide 6.6 heat and UV stabilized (PA66HSUV)
Material Shortcut	PA66HSUV
Flammability	UL 94 V-2
UV Resistant (Yes/No)	Yes
Operating Temperature	-40°F to +230°F (-40°C to +110°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Certification/Specification	UL ANSI/UL 1565 UL ANSI/UL 62275
UL Recognized (US)	Yes
Package Quantity (Imperial)	5000

Package Quantity (Metric)	5000
Customs Number	3926909988
Reel Weight (Imperial)	4.8
Reel Weight (Metric)	2.46

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).