


Specification Sheet

Part Number: 151-03037

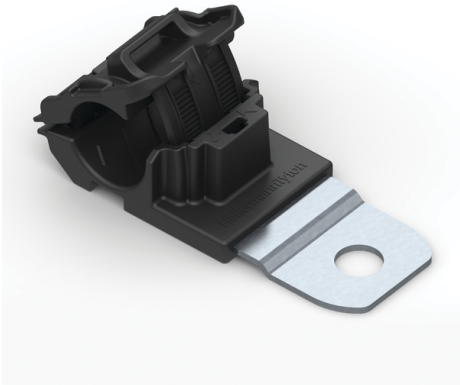

One-piece ratchet closure design allows for easy installation during pre- or final assembly.

Four sizes and multiple configurations handle a wide range of diameters and applications, reducing part inventory.

Clamp interior is designed to guide and center bundle to reduce pinching.

Easy release feature allows for quick adjustments and maintenance.

Impact modified, heat and UV stabilized PA66 provides long-term durability, indoors and out.

Soft material inserts are available for sensitive bundles.

For pre-determined clamp pressure, a Tension Tab is available for use with our EVO Series hand tools.

Ratchet P-Clamp, 0.50 - 0.77" Bundle Dia, 180° Short, 0.41" Hole Dia, PA66HIRHSUV/ST/ZN, Black, 20/bg

Article Number	151-03037
Type	RCB180SM10
Color	Black (BK)
Quantity Per	bag
Product Description	Ratchet P-Clamp, 0.50 - 0.77" Bundle Dia, 180° Short, 0.41" Hole Dia, PA66HIRHSUV/ST/ZN, Black, 20/bg

Short Description	Ratchet P-Clamp, 0.50 - 0.77" Bundle Dia, 180° Short, 0.41" Hole Dia, PA66HIRHSUV/ST/ZN, Black, 20/bg
Global Part Name	RCB180SM10-PA66HIRHSUV/ST/ZN-BK
Minimum Tensile Strength (Imperial)	100.0
Minimum Tensile Strength (Metric)	445
Length L (Imperial)	4.57
Length L (Metric)	116.2
Fixation Method	Screw Mounting
Variant	Short
Width W (Imperial)	1.37
Width W (Metric)	34.9
Bundle Diameter Min (Imperial)	0.5
Bundle Diameter Min (Metric)	12.7
Bundle Diameter Max (Imperial)	0.77
Bundle Diameter Max (Metric)	19.5
Mounting Hole Diameter D (Imperial)	0.405
Mounting Hole Diameter D (Metric)	10.29 mm

Stud Diameter (Metric)	M10
Mounting Hole Centers (Imperial)	2.08
Material	Steel (ST) Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV) Zinc plated (ZN)
Material Shortcut	PA66HIRHSUV ZN ST
Flammability	UL 94 HB
Halogen Free	Yes
UV Resistant (Yes/No)	Yes
Plenum Rating	AH-2
Operating Temperature	-40°F to +221°F (-40°C to +105°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
UL Listed (US and Canada)	Yes
UL Listed (US)	Yes
Package Quantity (Imperial)	20

Package Quantity (Metric)	20
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)