

SLIDE SWITCH

碩方精密電子開關

 www.Sofeng.com

Operation:DIP/插件立式 大型 拨动开关 [柄长可定制]



LTEM NO: SS-12D00

(Series)

(L8.8 × W3.9 × H7.2mm)


表面插装 DIP

正向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

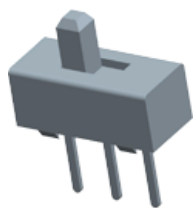

SS-12D00 G□


柄长
G2=2.0mm
G3=3.0mm
G4=4.0mm
G10=10.0mm

产品型号

Technical parameter

PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		0.5A, 24V DC	
	Initial Contact Resistance		50mΩ max.	
	Insulation Resistance		100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage		300V AC for 1 minute	250 V AC for 1 minute
Durable Performance	There No Load		15,000 Cycles	10,000 Cycles
	Rated Load		12,000 Cycles	8,500 Cycles
Storage temp.			-35℃~+75℃(Operating Temp:)	
Operating Force			3.5N. (1N.=100gram-force)	
Heat Rrsistance			IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

CIRCUIT DIAGRAM

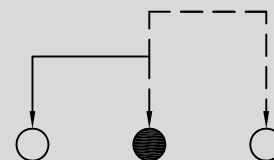

Unit:mm

P.C.B LAYOUT

