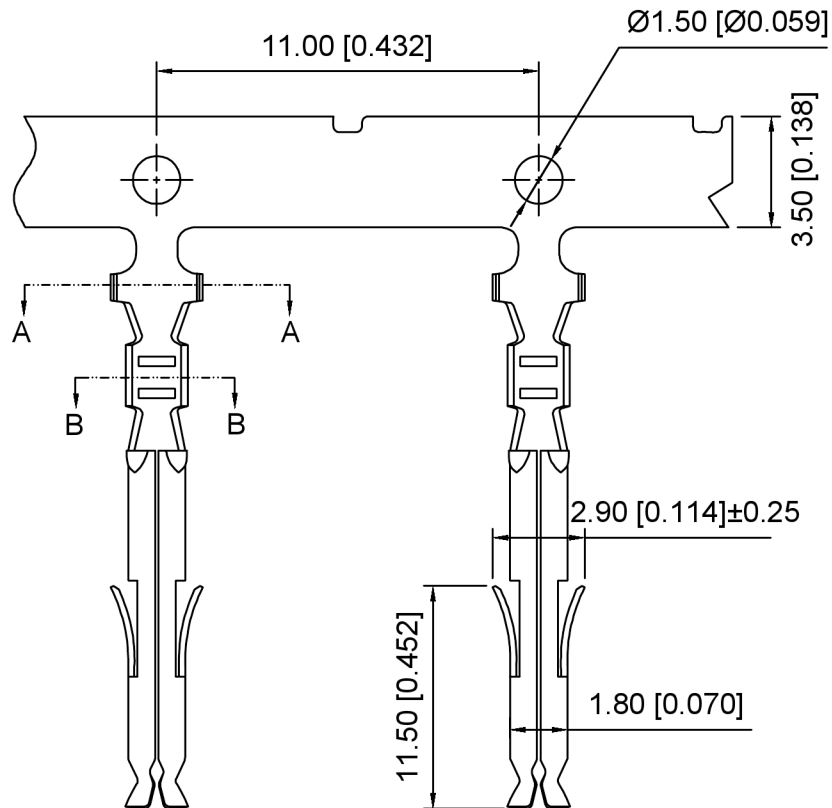


Specifications:

规格:

Voltage rating: 600V AC/DC
 额定电压: 600V AC/DC
 Current rating: 7A AC/DC
 额定电流: 7A AC/DC
 Withstanding voltage: 1500V AC/minute
 耐受电压: 1500V AC/分钟
 Temperature range: -40°C~+125°C
 温度范围: -40°C~+125°C
 Insulation resistance: 1000MΩ min
 绝缘电阻: 1000MΩ min
 Contact resistance: 20mΩ max
 接触电阻: 20mΩ max

X4140 T F - B SN
 ① ②③④ ⑤

1. Series No
2. Category: T-Terminal
3. Category: F-Female Terminal
4. Material: B-Brass
5. Finish: SN-Tin-plated

X4140TF-BSN	Brass	Tin-plated	AWG22#-26#	X4140HM
PART NO	Material	Finish	Wire Range	Suitable XKB Housing

DSND		SCALE: N/A	MODEL TYPE: 4.14mm Crimp Style Connector		
DWN		VIEW: 	PART NO.: X4140TF-BSN		
CHKD		UNIT: mm/in	DWG NO.: X-X4140TF-BSN		
APPD		SIZE: A4			
PRECISION CO.,LIMITED			WEIGHT	SHEET	REVISION
				1/1	A0

XKB

XKB INDUSTRIAL PRECISION CO., LIMITED

					ANGULAR	±5°
ΔX					L ≤ 4	±0.2
ΔX					4 < L ≤ 16	±0.3
ΔX					16 < L ≤ 63	±0.4
MARK					L > 63	±0.5
REVISIONS					UNSPECIFIED TOLERANCES	
www.helloxkb.com www.helloxkb.cn www.xk-dg.cn						