

Recommended Panel cut-out

Order NO. Description

78011 - XX

SERIES

Mini-change(7/8"),female
Front fastened,Solder type


POLES

03=3Poles
04=4Poles
05=5Poles

Technical specifications:

- Rated voltage/current:
3P 300V/13A
4P 300V/13A
5P 300V/9A
- Degree of protection:IP67
- Temperature range:-25°C~+80°C
- Mating cycles:≥500
- Contact resistance:≤5mΩ

Pin Assignment

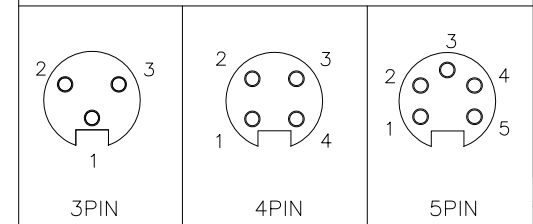

5	Pin	Brass; Gold-plated	3~5
4	O-Ring	Rubber, Black	1
3	Nut	Brass; Nickel plated	1
2	Body	7/8" female Shell, Brass; Nickel plated	1
1	Housing	TPU,Black	1
No.	PART NAME	DESCRIPTION	Q'TY

-TOLERANCES- UNLESS OTHERWISE SPECIFIED	DOSIN INDUSTRIAL(HK)CO.,LTD 江门市德索连接器有限公司 Jiangmen Dosin Connector Co., LTD Web: https://www.dosinconn.cn/ Mailbox: sale@dosin.cn Tel: (0086)769-81153905				
	PART DESCRIPTION: 7/8" female connector, Panel Mount, Front fastened,Solder type				
UNLESS OTHERWISE SPECIFIED TOLERANCES FOR MILLIMETERS ARE: 0.5 - 8mm ± 0.20mm 8 - 30mm ± 0.25mm 30 - 120mm ± 0.30mm	Appr: JIM.KING	P/N: DS869FCS0511			
	Check:	Date	Scale	Unit	Type
	Draw: DING	2022.12.06	Free	MM	Z
					Page
					1/1