

Recommended Panel cut-out

Order NO. Description

78011 - XX

SERIES

Mini-change(7/8"),female  
Front fastened,Solder type

POLES

03=3Poles  
04=4Poles  
05=5Poles

Technical specifications:

1. Rated voltage/current:

3P 300V/13A

4P 300V/13A

5P 300V/9A


2. Degree of protection:IP67

3. Temperature range:-25°C~+80°C

4. Mating cycles:≥500

5. Contact resistance:≤5mΩ

Pin Assignment

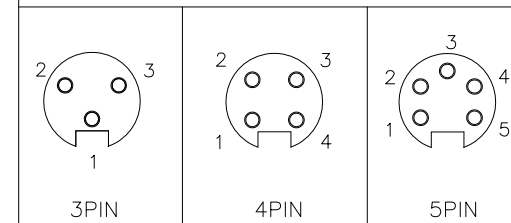

5	Pin	Brass; Gold-plated	3~5
4	O-Ring	Rubber, Black	1
3	Nut	Brass; Nickel plated	1
2	Body	7/8" female Shell, Brass; Nickel plated	1
1	Housing	TPU,Black	1
No.	PART NAME	DESCRIPTION	Q'TY

-TOLERANCES- UNLESS OTHERWISE SPECIFIED	DOSIN INDUSTRIAL(HK)CO.,LTD 江门市德索连接器有限公司 Jiangmen Dosin Connector Co., LTD Web: <a href="https://www.dosinconn.cn/">https://www.dosinconn.cn/</a> Mailbox: <a href="mailto:sale@dosin.cn">sale@dosin.cn</a> Tel: (0086)769-81153905				
	PART DESCRIPTION: 7/8" female connector, Panel Mount, Front fastened,Solder type				
UNLESS OTHERWISE SPECIFIED TOLERANCES FOR MILLIMETERS ARE: 0.5 - 8mm ± 0.20mm 8 - 30mm ± 0.25mm 30 - 120mm ± 0.30mm	Appr: JIM.KING	P/N: DS869FCS0511			
	Check:	Date	Scale	Unit	Type
	Draw: DING	2022.12.06	Free	MM	Z
					Page
					1/1