

Recommended Panel cut-out

Technical specifications:

- Rated voltage/current:
  - 3P 300V/13A
  - 4P 300V/13A
  - 5P 300V/9A
- Degree of protection: IP67
- Temperature range: -25°C ~ +80°C
- Mating cycles: ≥500
- Contact resistance: ≤5mΩ

Order NO. Description

78009 - XX


SERIES

Mini-change(7/8"),Male  
Front fastened,Solder type

POLES

03=3Poles  
04=4Poles  
05=5Poles

Pin Assignment

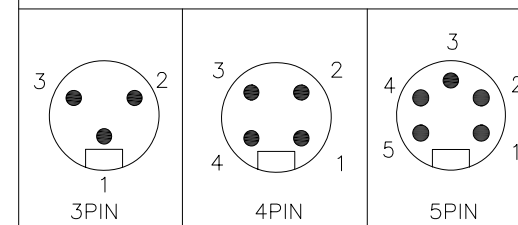

5	Pin	Brass; Gold-plated	3~5
4	O-Ring	Rubber, Black	1
3	Nut	Brass; Nickel plated	1
2	Body	7/8" male Shell, Brass; Nickel plated	1
1	Housing	TPU,Black	1
No.	PART NAME	DESCRIPTION	Q'TY

-TOLERANCES- UNLESS OTHERWISE SPECIFIED	DOSIN INDUSTRIAL(HK)CO.,LTD 江门市德索连接器有限公司 Jiangmen Dosin Connector Co., LTD Web: <a href="https://www.dosinconn.cn/">https://www.dosinconn.cn/</a> Mailbox: sale@dosin.cn Tel: (0086)769-81153906				
	PART DESCRIPTION: 7/8" male connector, Panel Mount, Front fastened,Solder type				
UNLESS OTHERWISE SPECIFIED TOLERANCES FOR MILLIMETERS ARE: 0.5 - 8mm ± 0.20mm 8 - 30mm ± 0.25mm 30 - 120mm ± 0.30mm	Appr:	JIM.KING			
	Check:	Date	Scale	Unit	Type
	Draw:	2022.12.06	Free	MM	Z
P/N:		DS869MCS0509			Page
					1/1