

Recommended Panel cut-out

Order NO. Description

78011 - XX

SERIES

Mini-change(7/8"),female  
Front fastened,Solder type


POLES

03=3Poles  
04=4Poles  
05=5Poles

Technical specifications:

- Rated voltage/current:  
3P 300V/13A  
4P 300V/13A  
5P 300V/9A
- Degree of protection:IP67
- Temperature range:-25°C~+80°C
- Mating cycles:≥500
- Contact resistance:≤5mΩ

Pin Assignment

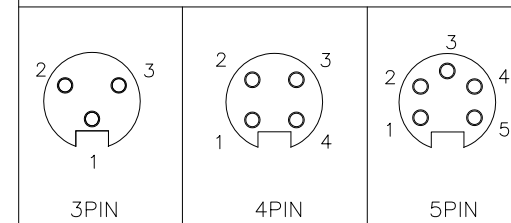

5	Pin	Brass; Gold-plated	3~5
4	O-Ring	Rubber, Black	1
3	Nut	Brass; Nickel plated	1
2	Body	7/8" female Shell, Brass; Nickel plated	1
1	Housing	TPU,Black	1
No.	PART NAME	DESCRIPTION	Q'TY

-TOLERANCES- UNLESS OTHERWISE SPECIFIED	DOSIN INDUSTRIAL(HK)CO.,LTD 江门市德索连接器有限公司 Jiangmen Dosin Connector Co., LTD Web: <a href="https://www.dosinconn.cn/">https://www.dosinconn.cn/</a> Mailbox: <a href="mailto:sale@dosin.cn">sale@dosin.cn</a> Tel: (0086)759-81153905					
	PART DESCRIPTION: 7/8" female connector, Panel Mount, Front fastened,Solder type					
UNLESS OTHERWISE SPECIFIED TOLERANCES FOR MILLIMETERS ARE: 0.5 - 8mm ± 0.20mm 8 - 30mm ± 0.25mm 30 - 120mm ± 0.30mm	Appr:	JIM.KING				
	Check:	Date	Scale	Unit	Type	Page
	Draw:	2022.12.06	Free	MM	Z	1/1

1

2

3

4

5

6

A

A

B

B

C

C

D

D

E

E

1

2

3

4

5

6