


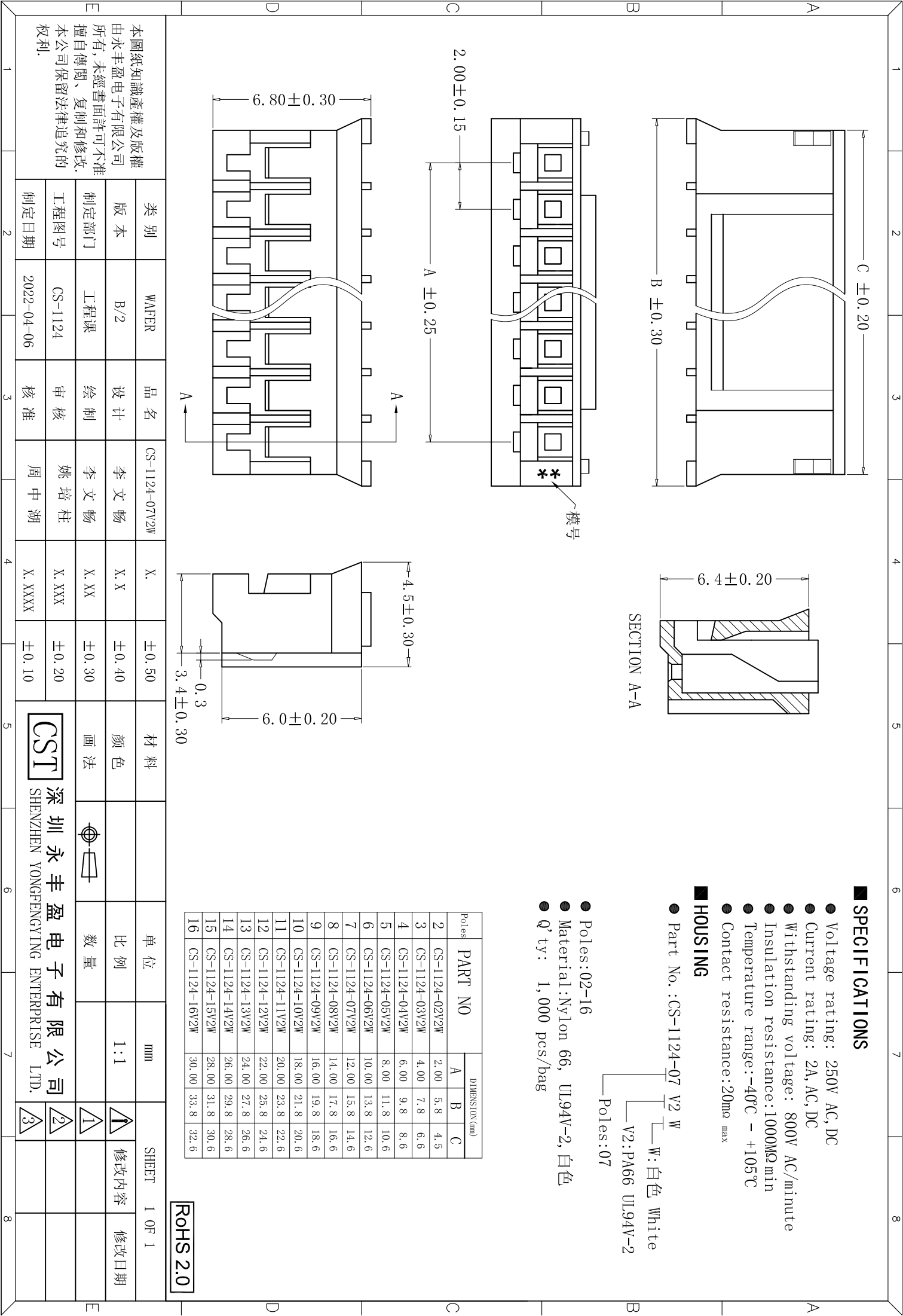

■ SPECIFICATIONS

- Voltage rating: 250V AC, DC
- Current rating: 2A, AC, DC
- Withstanding voltage: 800V AC/minute
- Insulation resistance: 1000MΩ min
- Temperature range: -40℃ - +105℃
- Contact resistance: 20mΩ max

■ HOUSING

- Part No.: CS-1124-07 V2 W
- Poles: 02-16
- Material: Nylon 66, UL94V-2, 白色
- Q'ty: 1, 000 pcs/bag

W: 白色 White  
V2: PA66 UL94V-2  
Poles: 07