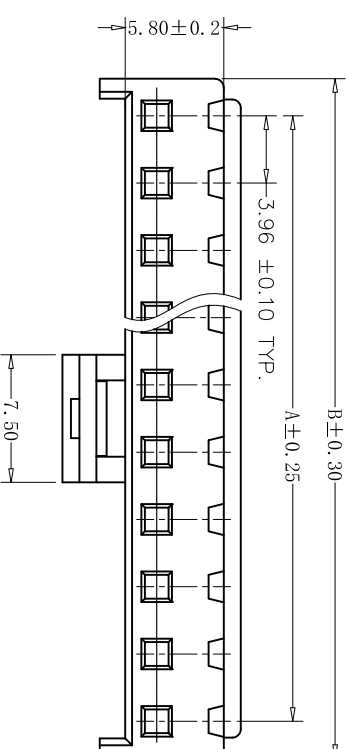


A		2		3		4		5		6		7		8	
															
B															

NO	PART NO	DIMENSION (mm)	
		A	B
2	CS-1121-02	3.96	8.2
3	CS-1121-03	7.92	12.2
4	CS-1121-04	11.88	16.2
5	CS-1121-05	15.84	20.2
6	CS-1121-06	19.8	24.2
7	CS-1121-07	23.76	28.2
8	CS-1121-08	27.72	32.2
9	CS-1121-09	31.88	36.2
10	CS-1121-10	35.64	40.2
11	CS-1121-11	39.60	44.2
12	CS-1121-12	43.56	48.2

SPECIFICATIONS

● Voltage rating: 250V AC, DC

● Current rating: 7A, AC, DC

● Withstanding Voltage: 1500V AC/minute

● Insulation resistance: 1000MΩ/min

● Temperature range: -40° C - +105° C

● Contact resistance: 20mΩ

HOUSING

● Part No.: CS-1121-06

● Part No.: 2-12

● Material: Nylon 66 UL94V-0, White

● Q' TY: 500/1000 pcs/Bag