
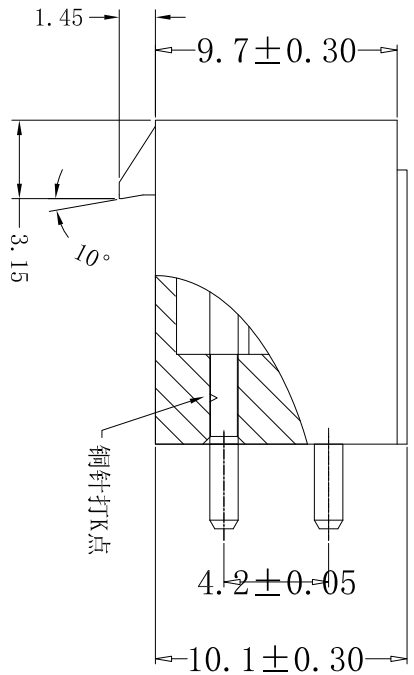



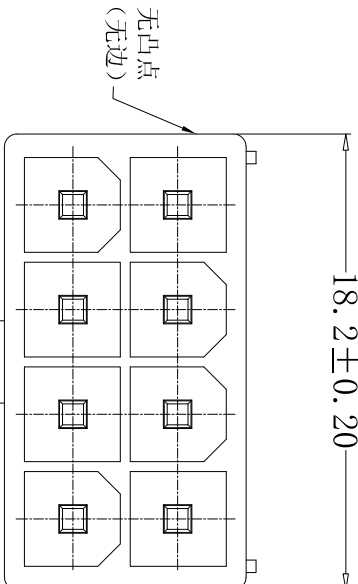


SPECIFICATIONS

- Voltage rating: 250V AC, DC
- Current rating: 7A-9A, AC, DC
- Withstanding voltage: 1500V AC/minute
- Insulation resistance: 1000MΩ_{min}
- Temperature range: -40℃ - +105℃
- Contact resistance: 10mΩ max

HOUSING

- Part No.: CS-1150-08CWVOT (0113)
- Poles: 08
- Material: Nylon 66, UL94V-0, 奶白色0113
- Q'TY: 250 pcs/bag
- CONTACT: H65, 7in 100u" OVER 50u" Ni

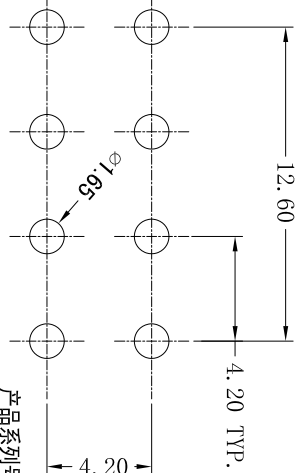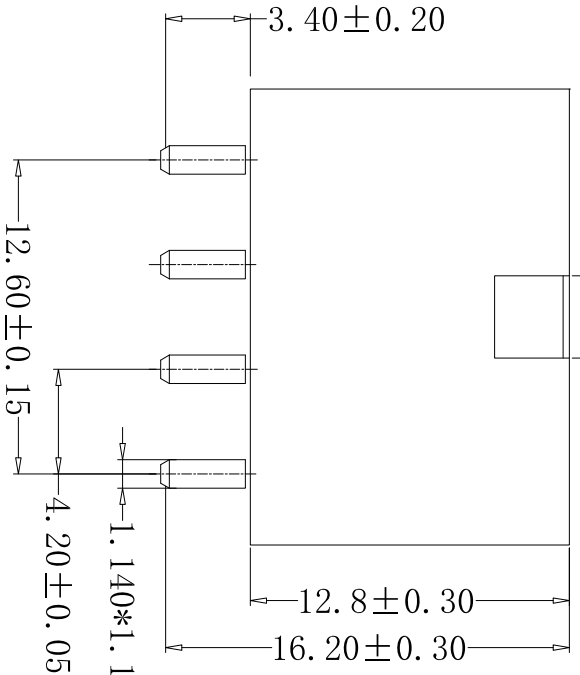

Recommend PCB Layout

RoHS 2.0

本圖紙知識產權及版權 歸深圳市永丰盈电子有 限公司所有，未經書面 許可不准擅自傳閱、复 制和修改。本公司保留 法律追究的权力。											
类别	针座	品名	CS-1150-08CWVOT (0113)			材料	单位	mm	SHEET 1 OF 1		
版本	A/0	设计	李文畅	X.X	±0.30	颜色	比例	1:1		修改内容	修改日期
制定部门	ENGINEER DEPARTMENT	绘制	李文畅	X.XX	±0.20	画法		数量			
工程图号	CS-1150-08CGBT	审核	姚培柱	X.XXX	±0.10	CST 深圳市永丰盈电子有限公司 ShenZhenYongFengYing ELECTRONICS CO., LTD.					
制定日期	2023-02-01	核准	周中湖	X.XXXX	±0.05						

本圖紙知識產權及版權
歸深圳市永丰盈电子有
限公司所有,未經書面
許可不准擅自傳閱、复
制和修改. 本公司保留
法律追究的权力.