


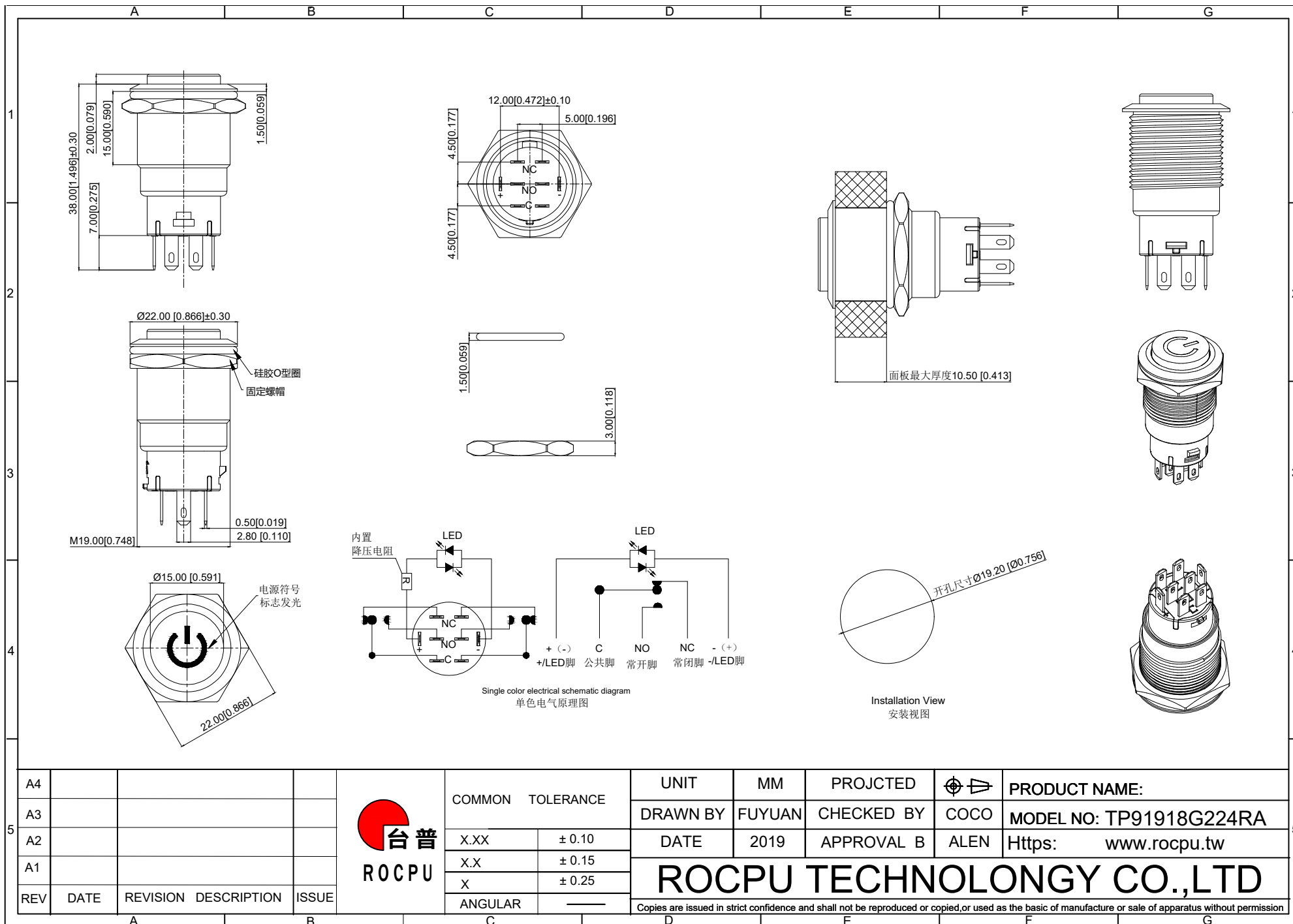

A4					 台普 ROCPO	COMMON TOLERANCE		UNIT	MM	PROJECTED		PRODUCT NAME:
A3								DRAWN BY	FUYUAN	CHECKED BY	COCO	MODEL NO: TP91918G224RA
A2						X.XX	± 0.10	DATE	2019	APPROVAL B	ALEN	Https: www.rocpcu.tw
A1						X.X	± 0.15	ROCPO TECHNOLOGY CO.,LTD				
REV	DATE	REVISION	DESCRIPTION	ISSUE		X	± 0.25					
						ANGULAR	—	Copies are issued in strict confidence and shall not be reproduced or copied, or used as the basic of manufacture or sale of apparatus without permission				

A		B		C		D		E		F		G	
1	性能参数												
	1. Heating current: Ui: AC250V, Ith: 5A 发热电流: Ui: AC250V, Ith: 5A						13. Electrical life: 500000 cycles 电气寿命: 500000 cycles						
	2. Rated current:3A/DC36V 额定电流:3A/DC36V						14. mechanical: 500000cycles 机械寿命: 500000cycles						
	3. Power-frequency withstand voltage:2000V1min 工频耐压:2000V1min						15. Operation method:Self repeating form 操作方式: 自复式						
	4. Insulation resistance:≥1000MΩ 绝缘电阻 :≥1000MΩ						16. NO reverse thrust foot torque: ≤30N NO反推脚扭力: ≤30N						
	5. Contact resistance:≤50mΩ 接触电阻 :≤50mΩ						17. LED lamp power consumption: 20m以下 LED灯功耗: 20m以下						
	6. Pressing stroke:3.00mm ± 0.10 按压行程:3.00mm ± 0.10						18. LED lamp lifespan: 40000h LED寿命: 40000h						
	7. Contact stroke:1.50mm±0.10 接触行程 :1.50mm±0.10						19. LED color: Red LED颜色: 红色						
	8. Nut assembly torque:5-14N 螺帽装配力矩:5-14N												
	9. Protection level:IP67 防护等级:IP67												
2													
	10. Explosion prevention level: IK10 防暴等级: IK10												
	11. Working environment temperature: -20 ℃~+55 ℃ 工作环境温度: -20 ℃~+55 ℃												
	12. Compression torque: ≤ 6N 按压扭力: ≤6N												
	连接形式												
	1. Welding temperature of wire: 320 ± 20 ℃ 线材焊接温度: 320±20℃ Wire welding duration: less than 3 seconds 线材焊接时长: 时长3秒以下												
	2. Can be used with dedicated connectors: 可配专用接插件使用:												
	2.1 1NO1NCSwitch function wire: green (C) blue wire (NO) yellow wire (NC) 1NO1NC开关功能线材: 绿色(C) 蓝线 (NO) 黄线 (NC)												
	2.2 2NO2NC switch function wire: green black wire (C), blue black wire (NO), yellow white wire (NC) 2NO2NC开关功能线材: 绿黑线 (C)、蓝黑线 (NO)、黄白线(NC)												
	2.3 LED functional wire: red wire positive pole, black wire negative pole, LED without distinction between positive and negative poles LED功能线材: 红线正极, 黑线负极, LED不分正负极												
3													
4													
5													

A					B					C					D					E					F					G				
材质参数																																		
10					luminous zone 发光区					PC 塑料					1																			
9					LEDpin LED脚					Brass 黄铜					1					Silvering 镀银														
8					Base 底座					PA46					1																			
7					Pin 引脚					Brass 黄铜					1					gold-plating 镀金														
6					Contact material 接触材质					silver alloy 银合金					1																			
5					LED Base LED基座					PC 塑料					1																			
4					Arm nut 固定螺帽					Brass 黄铜					1					nickeling 镀镍														
3					Oring O型圈					Silica gel 硅胶					1																			
2					Housing 外壳					Aluminum alloy 铝合金					1					Oxidized/Black 氧化/黑色														
1					Key 按键					Aluminum alloy 铝合金					1					Oxidized/Black 氧化/黑色														
NO 序号					Part name 部件名					Material 材料					QTY 数量					Remark 备注														

A4				 台普 ROCPCU	COMMON TOLERANCE		UNIT	MM	PROJECTED		PRODUCT NAME:
A3					X.XX	± 0.10	DRAWN BY	FUYUAN	CHECKED BY	COCO	MODEL NO: TP91918G224RA
A2					X.X	± 0.15	DATE	2019	APPROVAL B	ALEN	Https: www.rocpcu.tw
A1					X	± 0.25	ROCPCU TECHNOLOGY CO.,LTD				
REV	DATE	REVISION	DESCRIPTION		ISSUE	ANGULAR					