

2.4G shrapnel Antenna



PRODUCTS

Part No.	Weight	Dimensions (L x WxH)	Color
AIWM003	0.1g	17.8*6*8mm	Silver+Black

SPECIFICATIONS



PARAMETER	SPECIFICATION
Frequency Bands, MHz	2400-2500MHz
Nominal Impedance	50 Ω
Max Power (ambient temp of 25°C)	10 Watts
Color	Silver+Black
Storage Temperature Range (°C)	-40° C to +85° C
Operational Temperature Range (°C)	-40° C to +85° C
Material Substance Compliance	REACH/RoHS Compliant
HSCODE	8517707090
USHSCODE	8517620010
UPC	

MyAntenna RF Technology Co., Ltd


ADD: No.RM 405, R3-A Building, Shenzhen High-Tech Park, Nanshan, Shenzhen, P.R. China.

TEL: +86-0755-86503881 FAX: +86-0755-27801677 E-mail: nfc@myantenna.com

ELECTRICAL DATA

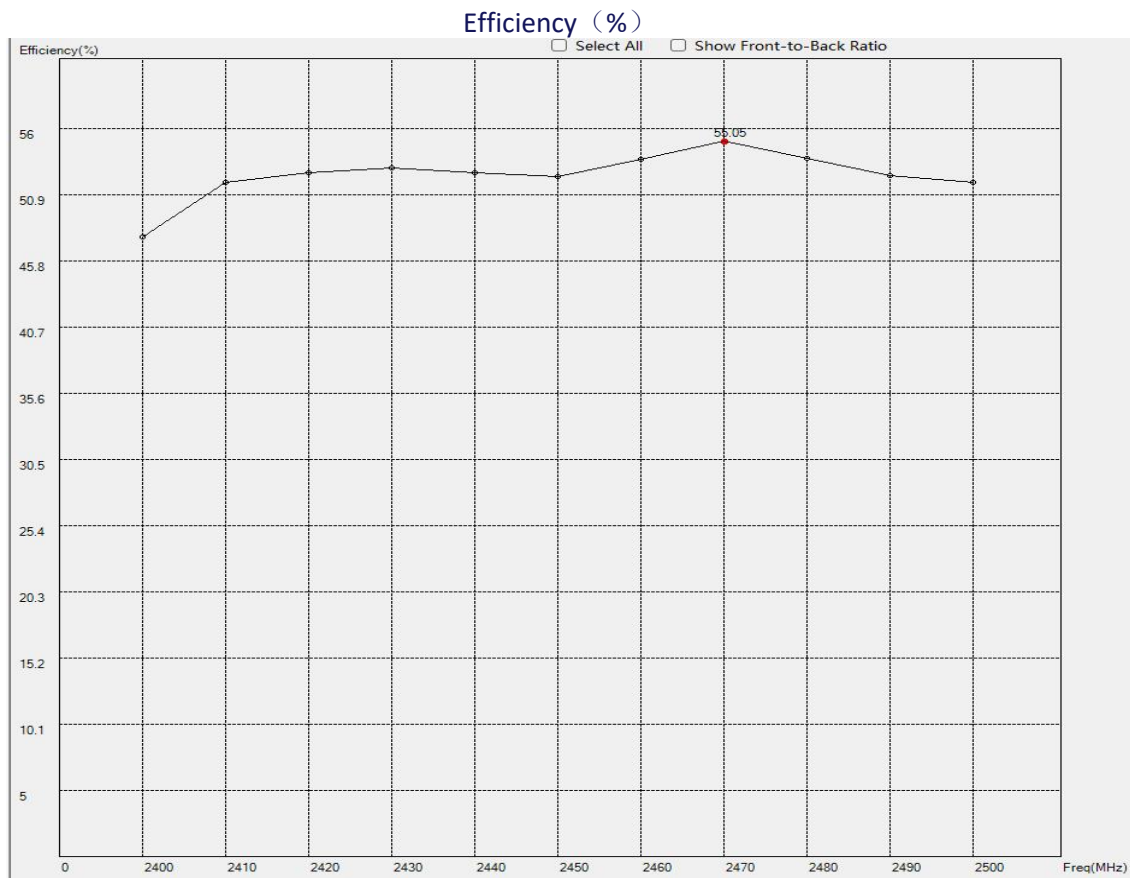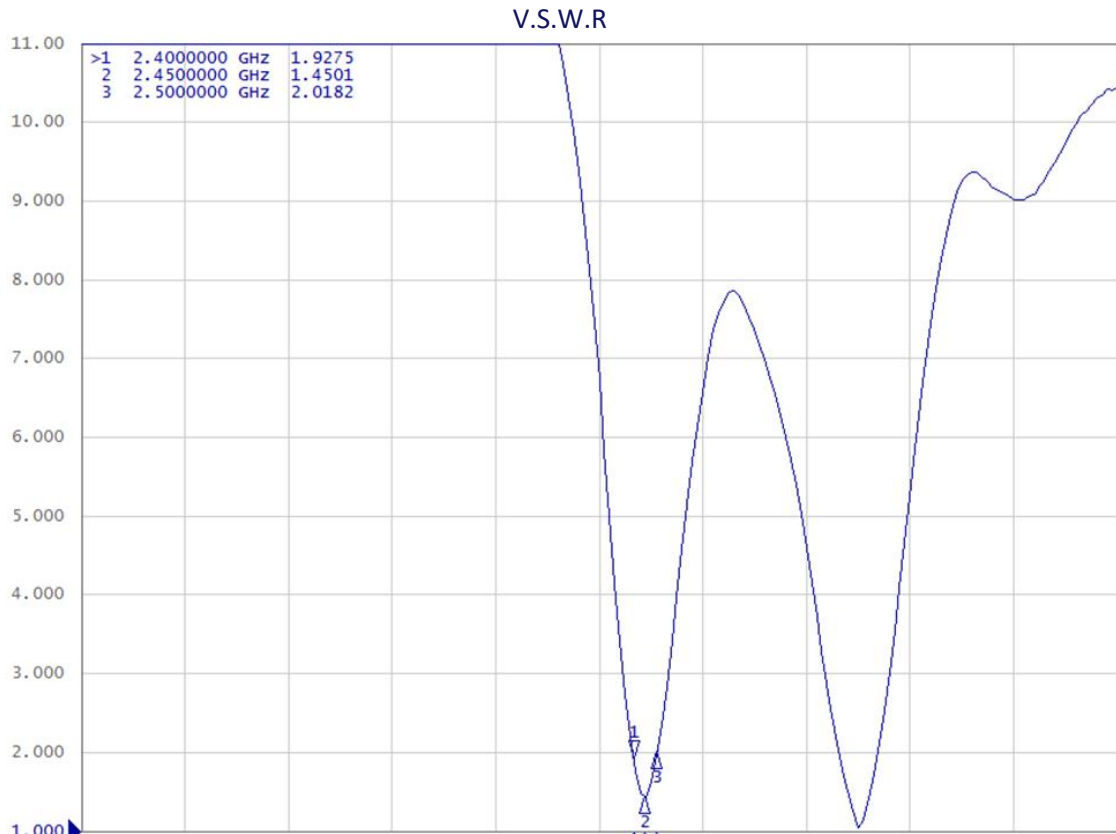


Peak Gain (dBi)

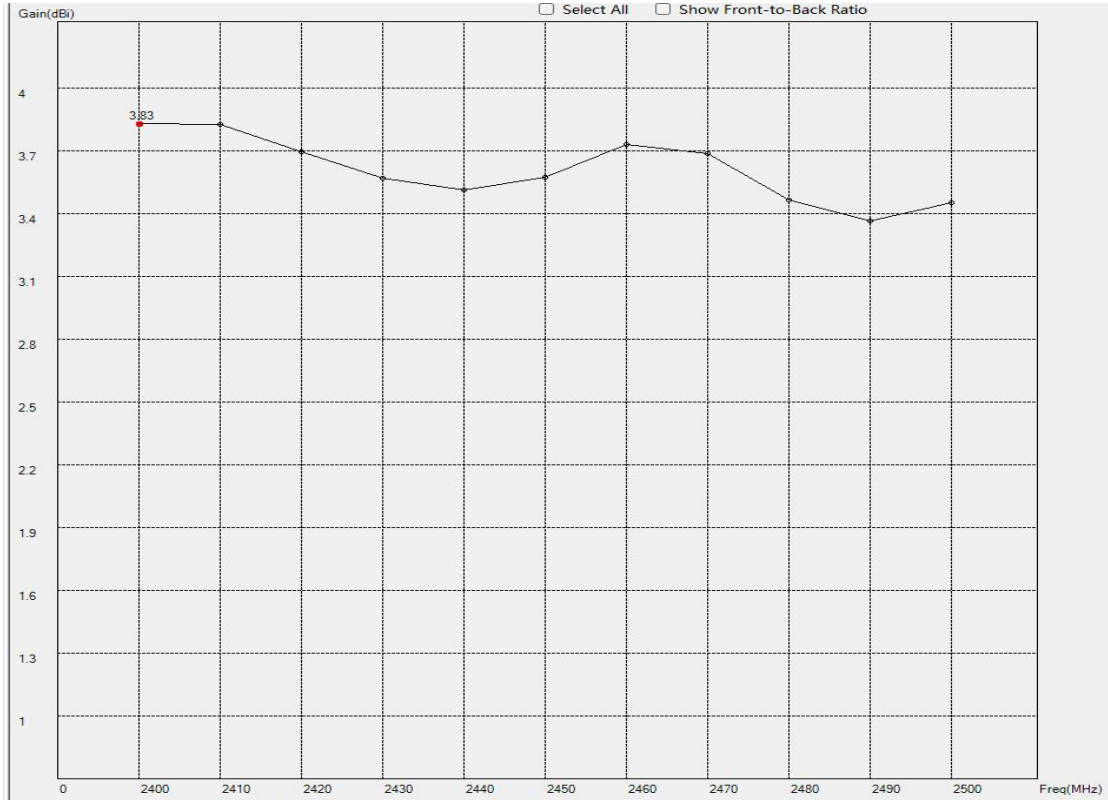

RADIATION PATTERNS

2D Radiation Pattern at 2450MHz

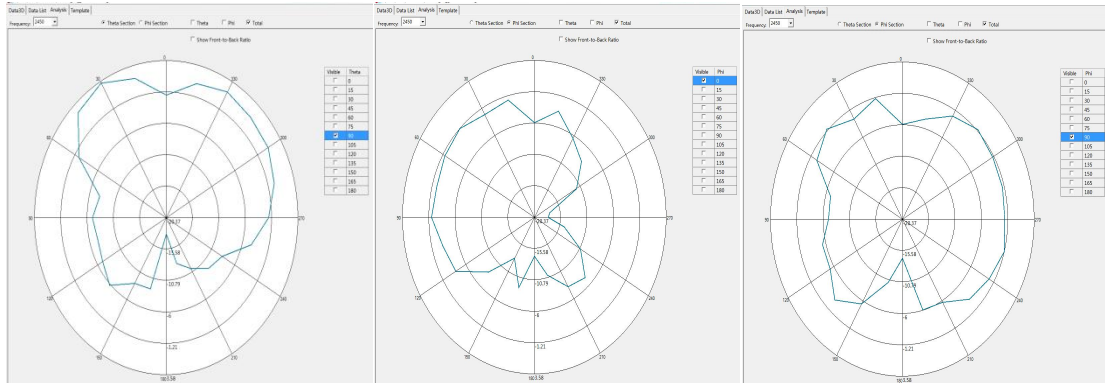

HOUSING CONFIGURATIONS

