


■ Features

- High Current Capability
- Low Forward Voltage Drop

■ Mechanical Data

- package:SOD-523
- Polarity: Color band denotes cathode end
- Flammability rating of epoxy resin: UL 94V-0
- Mounting Position: Any.

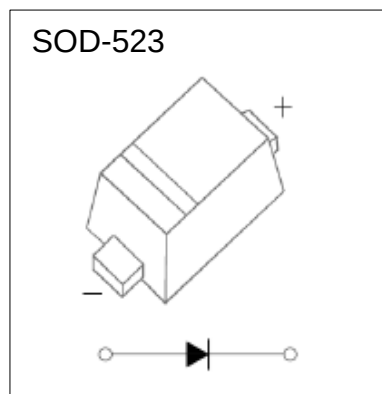

■ Ordering Information

Part Number	Package	Marking	Packing	Quantity per reel	Reel Size
LRB521S-40T1G	SOD-523	S	Tape & Reel	3000 PCS	7 inches

■ Maximum Ratings & Thermal Characteristics(Ratings at 25℃ ambient temperature unless otherwise specified.)




Parameters	Symbol	Limit	Unit
Peak reverse voltage	VRM	45	V
DC reverse voltage	VR	40	V
Mean rectifying current	Io	0.2	A
Peak forward surge current 8.3 ms single half sine-wave	IFSM	1.0	A
Typical thermal resistance	RθJA	667	℃/W
Power Dissipation	PD	150	mW
Storage temperature range	TSTG	-50-+150	℃



■ **Electrical Characteristics**(Ratings at 25 °C ambient temperature unless otherwise specified)


Parameters	Symbol	Test conditions	Min	Typ	Max	Unit
Maximum forward voltage	VF	IF = 10mA IF = 100mA IF = 200mA	0.16 0.31 0.41		0.30 0.45 0.54	V
Maximum reverse breakdown voltage	VR	IR=0.1mA	40			V
Maximum reverse current	IR	VR=10V VR=40V			20 90	uA

■ **Typical Characteristics**

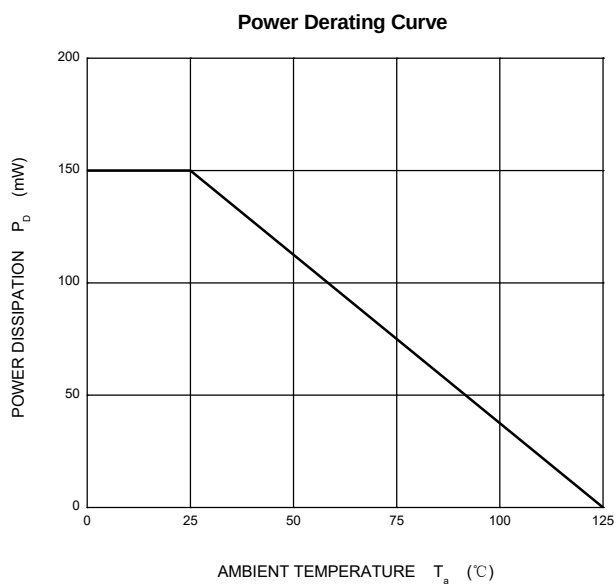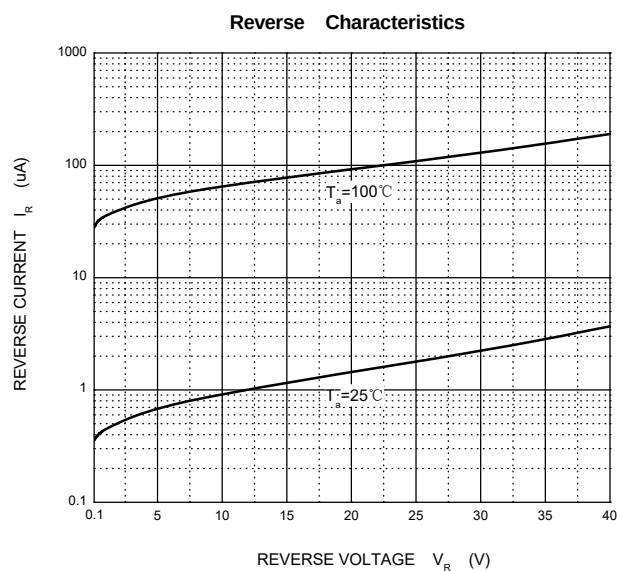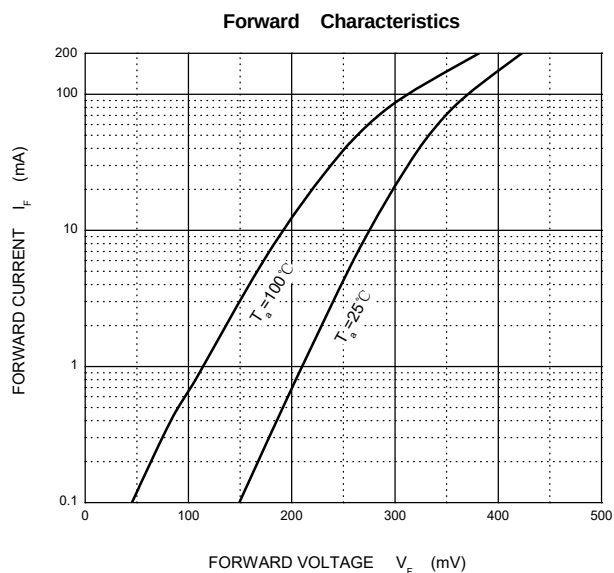



■ SOD-523 Package Outline Dimensions

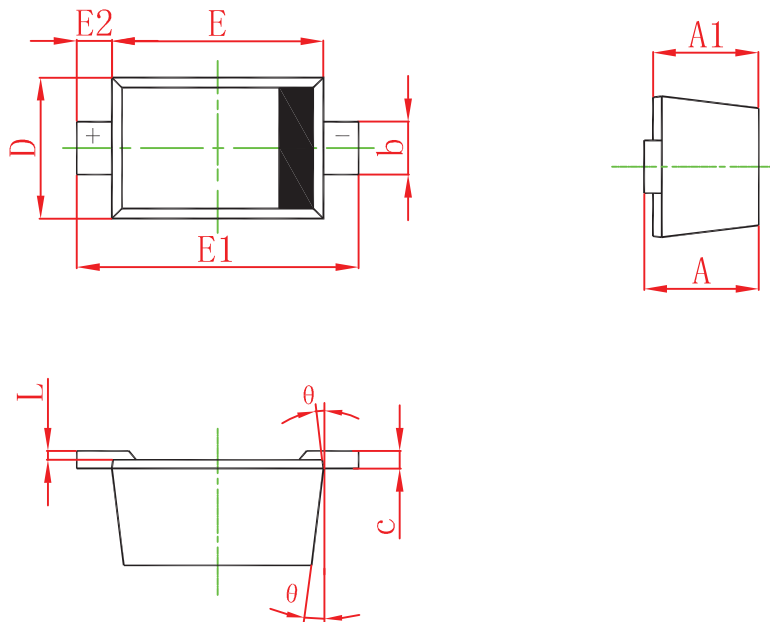

Sym ol	imensions In Millimeters		imensions In Inches	
	Min	Max	Min	Max
A	0.510	0.770	0.020	0.031
A1	0.500	0.700	0.020	0.028
b	0.250	0.350	0.010	0.014
c	0.080	0.150	0.003	0.006
D	0.750	0.850	0.030	0.033
E	1.100	1.300	0.043	0.051
E1	1.500	1.700	0.059	0.067
E2	0.200 REF		0.008 REF	
L	0.010	0.070	0.001	0.003
θ	7° REF		7° REF	