


## Heavy-Duty USB-C to Lightning Sync/Charge Cable with Status LED - MFi Certified, M/M, USB 2.0, 3 ft.

MODEL NUMBER: M102-003-HD-SL

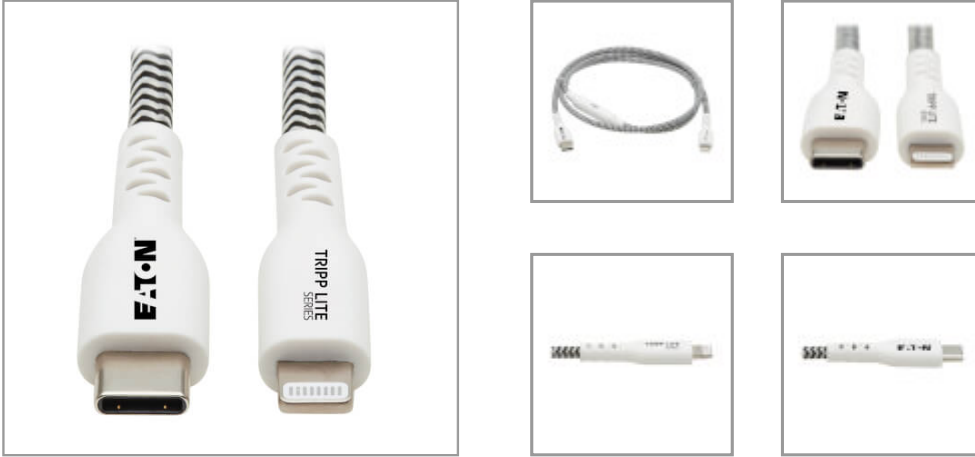

USB/Lightning cable connects your Apple iPhone, iPad or iPod to the USB-C port on your MacBook, laptop or wall/car charger.

### Features

#### 3 ft. USB-C Cable Charges and Syncs Your Latest-Generation iPhone, iPad and iPod

This USB-C sync/charge cable (M/M) connects your iPhone, iPad or iPod to the USB-C port on your MacBook Pro, Windows laptop, car charger or wall charger. It allows you to charge and power your Apple device, while simultaneously syncing and transferring image files and other personal data at USB 2.0 speeds up to 480 Mbps. The cable is backward compatible with previous USB generations, allowing you to use it with older equipment.

#### Bright LED Lets You Monitor Charge Status

An LED located on the cable allows you to keep track of your device's charging status at a glance, letting you know the device is fully charged without having to power it on. A blinking green LED indicates Normal Charging mode. A blue LED lets you know the cable is in Fast Charging mode. The LED turns off to tell you the connected device is fully charged. Note: Fast Charging is supported by iPhone 8 models and later only. Fast Charging occurs when the device's power is below 80%. When the device becomes 80% charged, charging mode switches to Normal.

#### Heavy-Duty Aramid Fiber Construction Designed to Endure the Stress of Everyday Use

The M102-003-HD-SL is tested to withstand over 150,000 bends without failing, thanks to its advanced bulletproof Aramid fiber construction. Its double-braided nylon exterior is built to withstand wear and tear over a long period. The nylon braiding also resists tangles while you're carrying the cable in your car, bag or briefcase. Integral strain relief gives the cable extra flexibility, reduces stress and helps the cable move freely without cracking or breaking loose from the connectors.

#### Reversible C94 Lightning and USB Type-C Plugs Connect in Either Direction

The reversible connectors plug into their respective ports in either direction for an instant connection every time. While the cable is compatible with all USB-C ports, the C94 Lightning connector is designed for optimal charging performance with Apple's 18W USB-C power adapter.

#### MFi-Certified for Broad Device Compatibility

The 20V 3A (60W) Lightning cable is MFi-certified for use with the latest generation of iPhone, iPad and iPod devices.

### Highlights

- Bulletproof Aramid fiber allows cable to bend over 150,000 times without failing
- Charging status LED on cable lets you know when your device is fully charged
- MFi-certified for broad compatibility with your Apple iPhone, iPad or iPod
- C94 Lightning connector is compatible with Apple 18W USB-C power adapter
- Durable double-braided exterior resists tangles and withstands long-term wear and tear

### Applications

- Charge and sync your Apple iPhone, iPad or iPod using the USB-C port on your computer or a wall charger up to 3 ft. away
- Transfer photos and other important files between an external hard drive and your Apple device
- Monitor your device's charge status with a glance at the cable's LED indicator
- Pair with an Apple 18W power adapter for optimal charging performance with an iPad Pro, iPad Air or iPhone 8 or later

### System Requirements

- Computer, laptop or charger with USB-C port
- Most current iPhone, iPad and iPod devices

### Package Includes

M102-003-HD-SL Heavy-Duty USB-C to Lightning Cable (M/M) with Status Light, 3 ft. (0.9 m)



Powering Business Worldwide

TRIPP LITE  
SERIES

## Specifications

OVERVIEW	
UPC Code	037332259769
Technology	Lightning; USB 2.0 (High Speed)
Cable Type	Passive
INPUT	
Maximum Input Amps	3
POWER	
USB Power Delivery (PD) Charging Support	Yes
CONNECTIONS	
Side A - Connector 1	USB C (MALE)
Side B - Connector 1	LIGHTNING (MALE)
Connector Plating	Nickel
Contact Plating	Gold
Connector Style	Straight
CHARGING	
Total Charging Watts	20
PHYSICAL	
Material of Construction	TPE, Aramid Fiber
Cable Jacket Color	Black; White
Cable Jacket Material	TPE
Cable Jacket Rating	VW-1
Cable Outer Diameter (OD)	4.2mm
Cable Length (ft.)	3
Cable Length (m)	0.91
Cable Length (in.)	36
Shipping Dimensions (hwd / in.)	0.90 x 2.40 x 4.70
Shipping Weight (kg)	0.05
Unit Packaging Type	Box
ENVIRONMENTAL	
Operating Temperature Range	-4° to 140°F (-20° to 60°C)



Powering Business Worldwide

TRIPP LITE  
SERIES

Storage Temperature Range	-4° to 176°F (-20° to 80°C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
Power Provided to Connected Device(s)	60W (20V/3A)
<b>FEATURES &amp; SPECIFICATIONS</b>	
USB Specification	USB 2.0 (up to 480 Mbps)
Data Transfer Rate	480 Mbps
Angled Plug	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	MFi
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.