

- [skip to Main Navigation](#)
- [skip to Main Content](#)
- [skip to Footer](#)

Our country websites

- [International](#)
- [Argentina](#)
- [Australia](#)
- [Austria](#)
- [Belgium](#)
- [Brazil](#)
- [Canada](#)
- [China](#)
- [Czech Republic](#)
- [Denmark](#)
- [Finland](#)
- [France](#)
- [Germany](#)
- [Hong Kong](#)
- [Hungary](#)
- [India](#)
- [Ireland](#)
- [Italy](#)
- [Japan](#)
- [Mexico](#)
- [Netherlands](#)
- [Norway](#)
- [Philippines](#)
- [Poland](#)
- [Portugal](#)
- [Republic of Korea](#)
- [Romania](#)
- [Russian Federation](#)
- [Singapore](#)
- [Slovenia](#)
- [South Africa](#)
- [Spain](#)
- [Sweden](#)
- [Thailand](#)
- [Turkey](#)
- [UAE](#)
- [United Kingdom](#)
- [United States](#)

[Catalogs](#)

[Blog](#)

[News](#)

[Careers](#)

[Distributor Login](#)

[Find A Distributor](#)



The site navigation utilizes arrow, enter, escape, and space bar key commands. Left and right arrows move across top level links and expand / close menus in sub levels. Up and Down arrows will open main level menus and toggle through sub tier links. Enter and space open menus and escape closes them as well. Tab will move on to the next part of the site rather than go through menu items.

Menu

- [Products](#)
 - [Featured Products](#)
 - [Cable Tie Tools](#)
 - [Bundling & Securing](#)
 - [Electrical Installation](#)
 - [Identification](#)
 - [Routing, Protection and Insulation](#)
- [Industries](#)
 - [Aerospace](#)
 - [Automotive](#)
 - [Defense](#)
 - [Energies - Solar](#)
 - [Energies - Wind](#)
 - [Industrial Automation](#)
 - [Machine and Equipment Builders \(OEMs\)](#)
 - [Medical Equipment](#)
 - [Rail](#)
 - [Truck/Heavy Equipment](#)
- [Resources](#)
 - [Cross Reference](#)
 - [Literature](#)
 - [Logo Downloads](#)
 - [Materials](#)
 - [Product Selector](#)
 - [Videos & Webinars](#)
 - [Modular Omega Clip Configurator](#)
- [About](#)
 - [About HellermannTyton](#)
 - [MADE FOR REAL](#)
 - [The HellermannTyton Difference](#)
 - [Sustainability](#)
 - [Environmental Management System](#)
 - [North American Locations](#)

- [Support](#)
 - [Customer Service](#)
 - [ID Solutions](#)
 - [Product Instructions](#)
 - [Product & Certification Training](#)
 - [Quality Certifications](#)
 - [Warranty Policies](#)
- [Sustainability](#)


Search

I'm looking for...

Search

Specification Sheet

Part Number: 151-01456

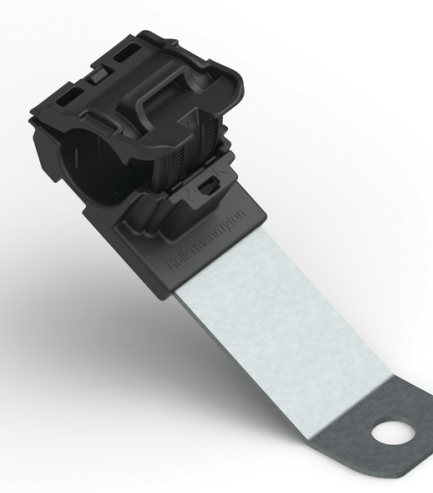

One-piece ratchet closure allows for easy installation during pre- or final assembly.
Easy release feature simplifies quick adjustments and maintenance.

Impact modified, heat and UV stabilized PA66 provides long-term durability, indoors and out.

Zinc-plated steel mounting plate tolerates high torque and is treated to resist chemicals and salt spray.

Angled mounting plates are ideal for stacking RPCs or for avoiding obstructions or heat sources.

Ratchet P-Clamp, 0.52 - 0.77" Bundle Dia, 30° Long, 0.51" Hole Dia, PA66HIRHSUV/ST/ZN, Black, 200/ctn

Article Number	151-01456
Type	RCB30LM12
Color	Black (BK)
Quantity Per	box
Product Description	The Ratchet P-Clamp family offers versatility when managing wires, cables and hoses. The robust design and durable materials make it ideal for heavy duty applications, both indoors and out. The one-piece adjustable clamp can be closed by hand to the desired diameter. The release feature provides easy and nondestructive removal of cables simply by using a flat-head screwdriver. This nondestructive release allows the clamp to be reused without removing or replacing any bolts or screws.
Short Description	Ratchet P-Clamp, 0.52 - 0.77" Bundle Dia, 30° Long, 0.51" Hole Dia, PA66HIRHSUV/ST/ZN, Black, 200/ctn
Global Part Name	RCB30LM12-PA66HIRHSUV/ST/ZN-BK

Minimum Tensile Strength (Imperial)	100.0
Minimum Tensile Strength (Metric)	445
Length L (Imperial)	5.93
Length L (Metric)	150.5
Fixation Method	Screw Mounting
Variant	Long
Width W (Imperial)	1.37
Width W (Metric)	34.9
Bundle Diameter Min (Imperial)	0.5
Bundle Diameter Min (Metric)	12.7
Bundle Diameter Max (Imperial)	0.77
Bundle Diameter Max (Metric)	19.5
Cable Tie Width Max (Imperial)	0.52
Cable Tie Width Max (Metric)	13.2
Mounting Hole Diameter D (Imperial)	0.510
Mounting Hole Diameter D (Metric)	12.95 mm
Mounting Hole Diameter D Max (Metric)	12.95
Stud Diameter (Metric)	M12
Mounting Hole Centers (Imperial)	2.89

Material	Zinc plated (ZN) Steel (ST) Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV)
Material Shortcut	ZN PA66HIRHSUV ST
Flammability	UL 94 HB
Halogen Free	Yes
UV Resistant (Yes/No)	Yes
Plenum Rating	AH-2
Operating Temperature	-40°F to +221°F (-40°C to +105°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
UL Listed (US and Canada)	Yes
UL Listed (US)	Yes

Package Quantity (Imperial)	200
Package Quantity (Metric)	200
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

HellermannTyton

Contact Us

[How Can We Help You?](#)

Find us worldwide

Follow Us

- [LinkedIn](#)
- [Twitter](#)

[Products](#)

- [Featured Products](#)
- [Cable Tie Tools](#)
- [Bundling & Securing](#)
- [Electrical Installation](#)
- [Identification](#)
- [Routing, Protection and Insulation](#)

[Industries](#)

- [Aerospace](#)
- [Automotive](#)
- [Defense](#)
- [Energies - Solar](#)
- [Energies - Wind](#)
- [Industrial Automation](#)
- [Machine and Equipment Builders \(OEMs\)](#)
- [Medical Equipment](#)
- [Rail](#)
- [Truck/Heavy Equipment](#)

[Resources](#)

- [Cross Reference](#)
- [Literature](#)
- [Logo Downloads](#)
- [Materials](#)
- [Product Selector](#)
- [Videos & Webinars](#)
- [Modular Omega Clip Configurator](#)

[About](#)

- [About HellermannTyton](#)
- [MADE FOR REAL](#)
- [The HellermannTyton Difference](#)
- [Sustainability](#)
- [Environmental Management System](#)
- [North American Locations](#)

[Support](#)

- [Customer Service](#)
- [ID Solutions](#)
- [Product Instructions](#)
- [Product & Certification Training](#)
- [Quality Certifications](#)
- [Warranty Policies](#)

© 2024 HellermannTyton. All Rights Reserved.

- [Contact Us](#)
- [RoHS/WEEE Compliance](#)
- [Disclaimer](#)
- [Terms and Conditions](#)