


 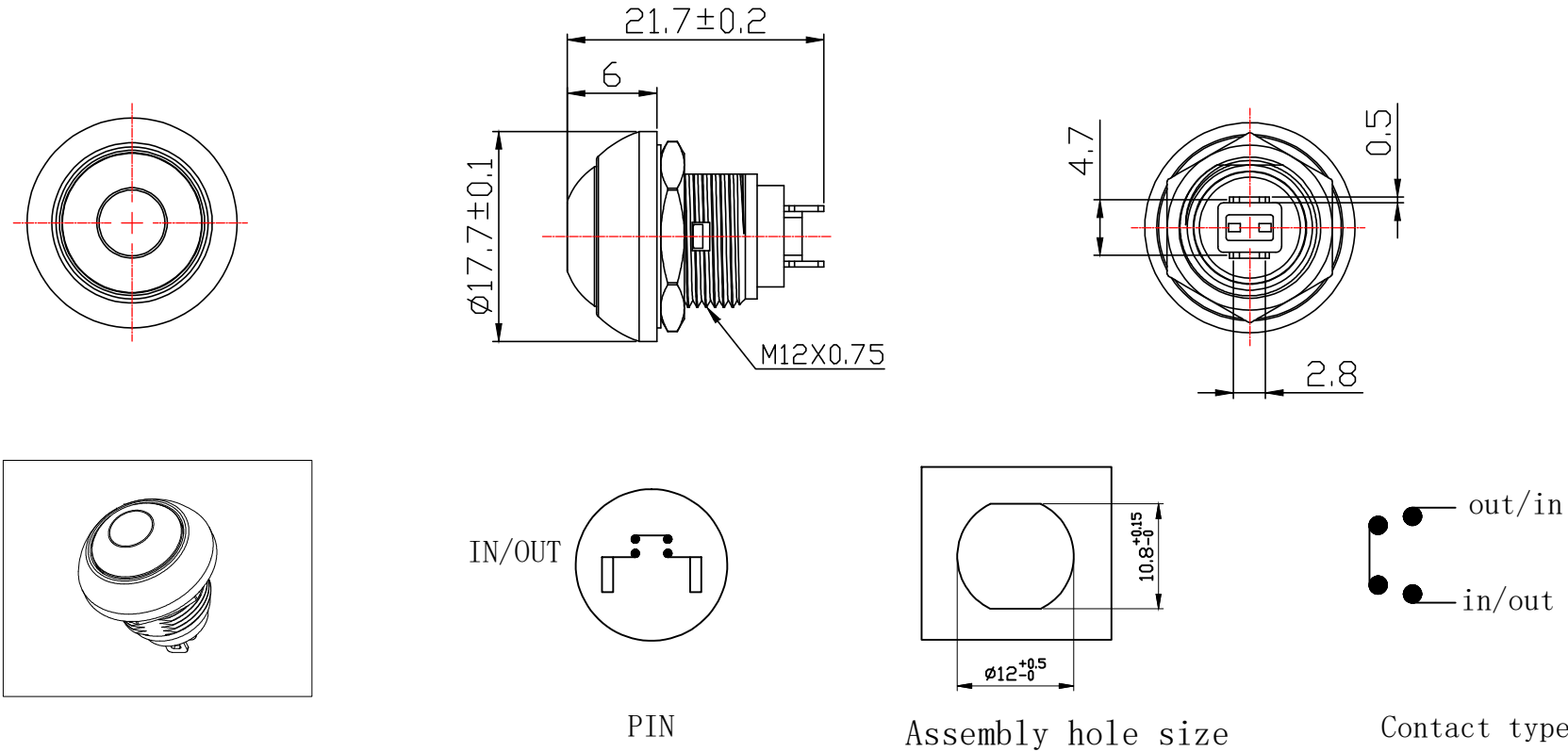


Specification

Packaging: 50pcs/box
LT: 10days Made in China

项目 Item	参数 Parameter	项目 Item	参数 Parameter
额定电压, 发热电流 Rating Insulation Voltage, Rated Thermal current	DC 250V 2A	动作力 Operating Force	按下 (Press): 5.5±0.55N 复位 (Spring-Return): 1±0.1N
使用温度 Ambient Temperature	-25℃~+55℃	电气寿命 Endurance	500000次
绝缘电阻 Insulated resistance	≥100MΩ	动作方式 Action Mode	自动制止 Maintained
接触电阻 Contact Resistance	≤25MΩ	开关行程 (MM) Route Of Travel. (MM)	动作行程 (Action Travel): 1.5 超行程 (Excess Travel): 1.5
LED 寿命 LED Endurance			

Type	Operating Force (gF)	Button	Leads Shape (G, J, T)	Ground pin (0, 1)	Pogo Option (0, 1)
YTS8P012NL	1	550±50	G Green	T	0
			Y Yellow		
			B Black		
			O Origin		
			R Red		
			W White		
			U Blue		

X. ±0.50	X.° ±2°	UNITS mm		深圳市怡远科技有限公司				
.X ±0.30	.X° ±1°			SHENZHEN YIYUAN TECHNOLOGY CO.,LTD				
.XX ±0.10	.XX° ±0.5°	MAT'L 	PART NO. YTS8P012NL		TITLE: PUSH SWITCH M12复位按动			
.XXX ±0.05								
THESE DRAWINGS SPECIFICATIONS ARE THE PROPERTY OF YIYUAN TECHNOLOGY CO.,LTD AND SHALL NOT BE REPRODUCED. COPIED OR USED IN ANY MANNER WITHOUT THE PRIOR WRITTEN CONSENT OF YIYUAN TECHNOLOGY CO.,LTD Email at info@yiyuanswitches.com		FINISH 	APPD: ROGER		DWG NO. : YTS8P012NL			
		Q' TY 	CHKD: ROC					
			DR: BILLY WANG 2020/08/21					
				SCALE SHEET REV. 1/1 1/1 A1				