




SMD PULSE TRANSFORMER


High Common Mode Impedance at High Frequency.
Excellent Noise Suppression Performance.
Small Size and Low Profile, Surface Mount Type.
Operating Temperature Range: -40 °C to +85 °C.
RoHS Compliant.

Part Number	Electrical Specifications @25°C				
	Common mode Impedance (ohm ±25%@100M)	DCR (Ω Max)	Rated Current mA Max	Rated Volt (Vdc)	IR M(Ω Min)
CC2012E-801	800	0.88	300	50	10


MECHANICAL

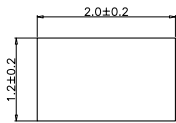


TOP VIEW

 

BOTTOM VIEW

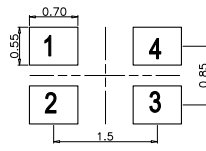


SUGGEST LAYOUT

 


SIDE VIEW

SCHEMATICS

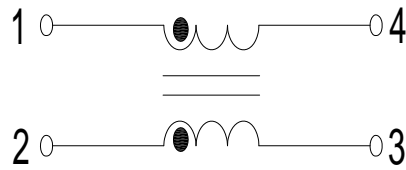


Unless otherwise specified all tolerances are:±0.25mm

TAPING AND PACKING

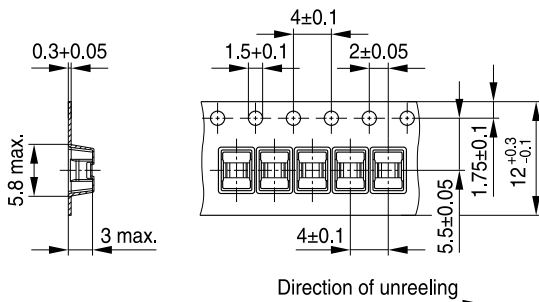

IND1752-J-E

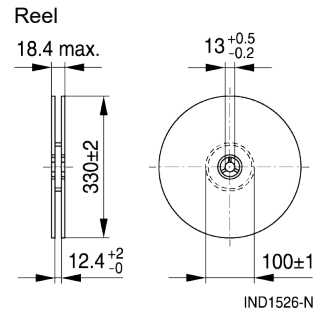

IND1526-N
Dimensions in mm

Quantity (pcs):
3000 PCS PER REEL
30 REELS PER CARTON
90000 PCS PER CARTON