

 
SMD PULSE TRANSFORMER




CHIP COMMON MODE CHOKE
Applications, Surface Mount Type.
Operating Temperature Range: -40 °C to +85°C
RoHS Compliant.

Part Number	Electrical Specifications @25°C					
	DCR (Ω Max)	WITHSTAND VOLT (Vdc Max)	Rated Current mA Max	Rated Volt (Vdc)	Common mode Impedance (ohm ±25%@100M)	IR M(Ω Min)
CC2012F-601	0.8	125	300	50	600	10


MECHANICAL




TOP VIEW

 

BOTTOM VIEW

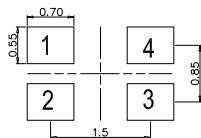


SUGGEST LAYOUT

 


SIDE VIEW

SCHEMATICS

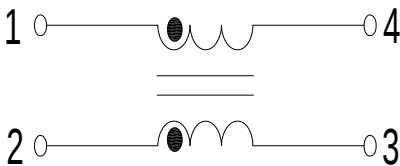


Unless otherwise specified all tolerances are:±0.25mm

TAPING AND PACKING

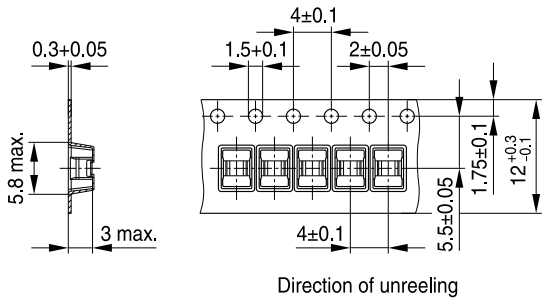

IND1752-J-E

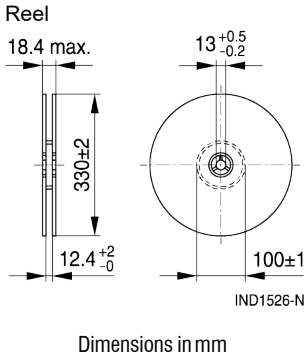

Dimensions in mm

Quantity (pcs):
3000 PCS PER REEL
30 REELS PER CARTON
90000 PCS PER CARTON