

Operation: SMT/立贴式 中大型 大行程 轻触开关 [柄长/操作力可定制]



ITEM NO.: TS-1217A-□ (Series)

(L8.4mm×W8.4mm TACT-SWITCH)

表面贴装 SMT

正向操作 DOWN

精密部品 NICETY

 
可靠 STABILIZE

適合環保 RoHS

Technical parameter

PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		0.5A, 24V DC	
	Initial Contact Resistance		50mΩ max.	
	Insulation Resistance		100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage		300V AC for 1 minute	250 V AC for 1 minut
	There No Load		100,000 Cycles	85,000 Cycles
	Rated Load		85,000 Cycles	60,000 Cycles
	Storage Temp		25℃/50℃RH (Operating temperature: -35℃~+75℃)	
	Operating Force		1.6 / 2.6N. (1N.=100gram-force)	
	Heat Rrsistance		IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

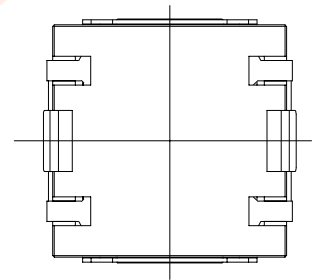
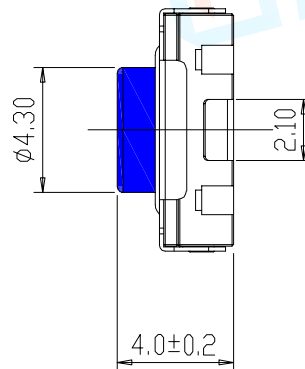
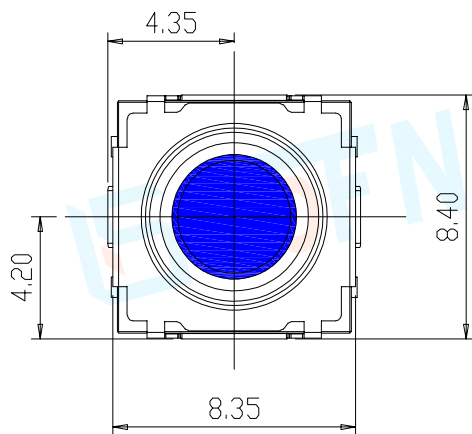
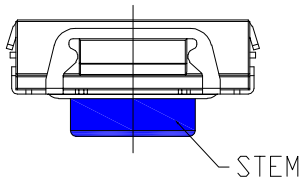
CIRCUIT DIAGRAM



Unit:mm

TS-1217A - **

产品型号

操作力度
26=2.6N
40=4.0N

P.C.B LAYOUT

