


RoHS
Compatible

REV.	DESCRIPTION	DATE
△	首次发行	2024-03-29

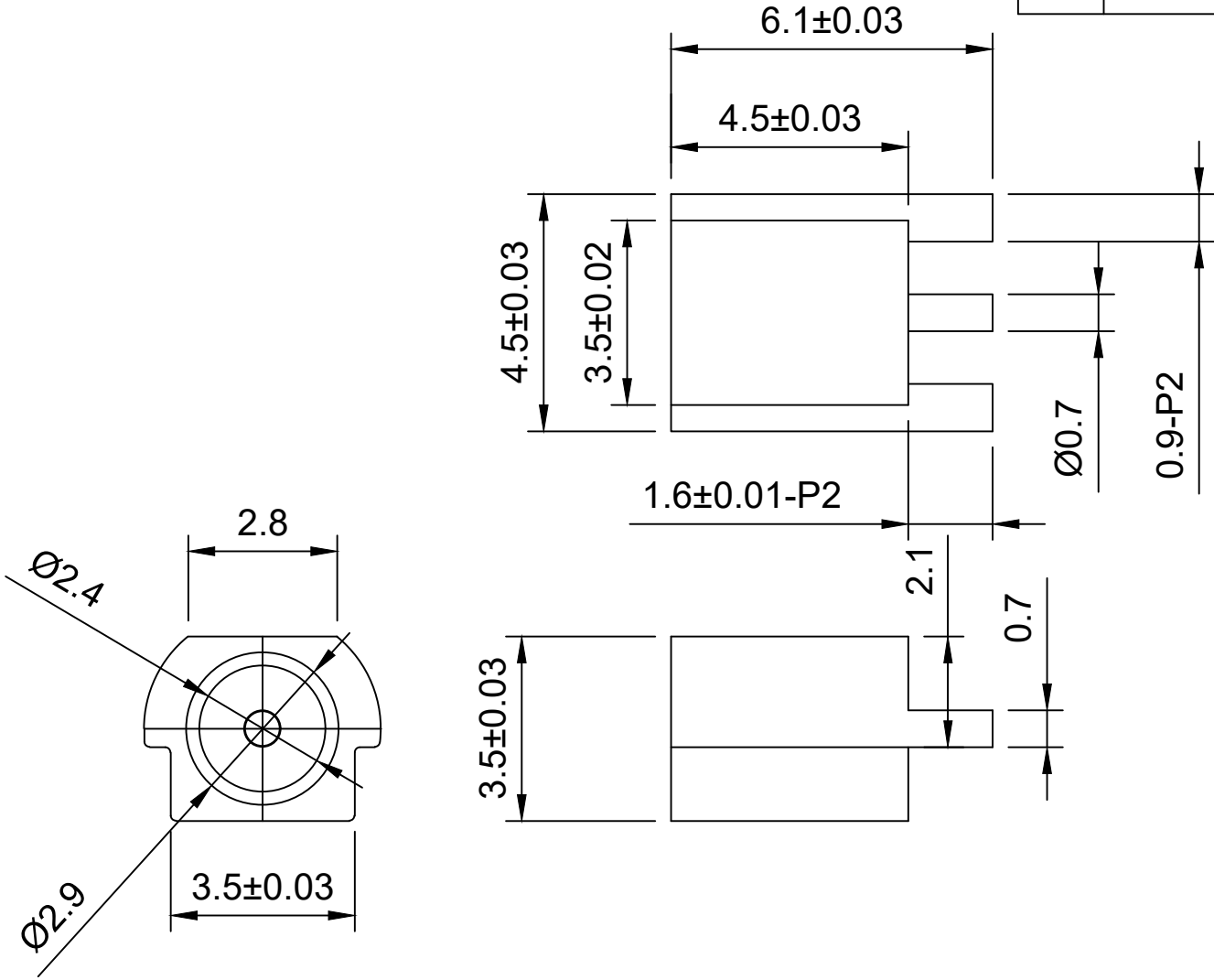

编号	图号	名称	材料	件数	备注
1	外壳	黄铜Hpb59-1	镀镍	1	
2	内导体(PIN)	黄铜Hpb59-1	镀金	1	
3	绝缘子	聚四氟乙烯	-	1	
4					
5					
6					
7					

Remark:

- Impedance standard 50 Ω
- Band range DC0~6G
- Voltage VSWR 1.3MAX
- Voltage rating 500 VRMS(Maximum sea level)
- Dielectric withstand voltage 1500 VRMS (Sea level minimum)
- Insulation resistance 500 MEGOHMS
- Operating temperature -55℃~+155℃
- Relative temperature $\leq 95\%$ (temperature 40℃+2℃)
- The surface products are ROHS compliant



东莞市众驰电子科技有限公司

Dongguan Zhongchi Electronic Technology Co.,Ltd

Tel 0769-81238620

Fax:0769-81238620

PART NAME: MMCX-KHE

PART NO.: ZC6.61KE1

DATE: 2024-03-29

APPROVED BY

CHECKED BY

DESIGNED BY

UNIT: mm

Tolerance

SCALE: 1/1

X.X ± 0.1

REVISION: A

X.XX ± 0.05

HWC

X° $\pm 1^\circ$