
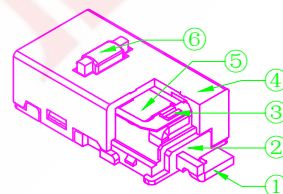
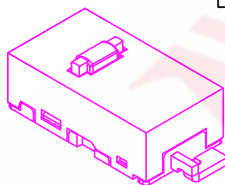
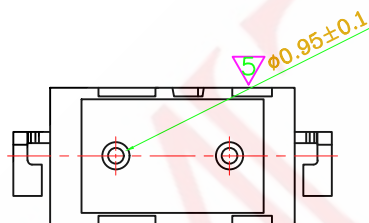
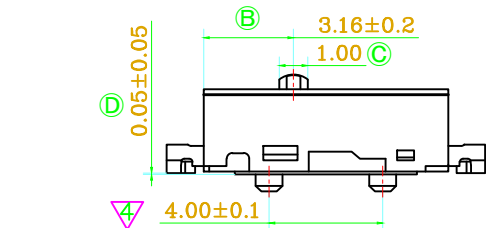
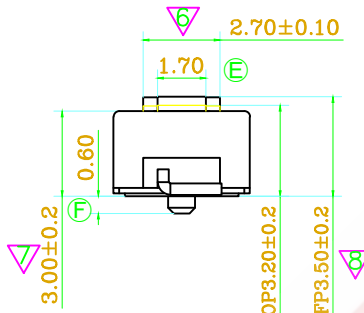


SAMZO REAC/ROHS

REV	ECN NO	DESCRIPTION	DESIGN	APPROVAL	DATE
A1	NEW	Replace frame			2018.06.14

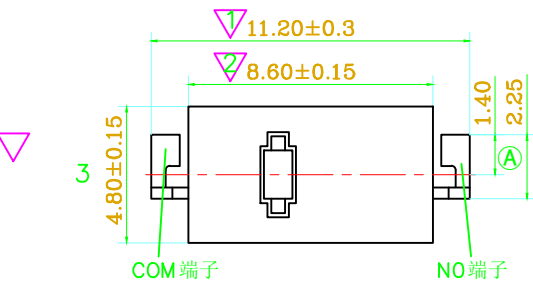


- A. 系列:4A:8.6系列微型
- B. 贴装方式:C-2P SMD
- C. 操作方式:A:点触
- D. 性能特性:B:1A 6V DC
- E:触点镀层:Y-银点
- F:操作力度:H-90gf
- G:使用寿命:F:5,000,000万次

4A C A B Y H F
 A B C D E F G

技数参数

1. 额定值:DC6V 1mA(最小负载DC3V 15μA)
2. 接触阻抗:100毫欧 最大
3. 绝缘阻抗:100兆欧最小(DC 500V)
4. 耐压:非接触端子间端子与外壳,端子与非载流金属部件间AC600V(50-60Hz)持续1分钟.
5. 容许操作速度:1~500mm/s
6. 容许操作频率:机械/电气最大300次/min
7. 操作力:90±30gf
8. 机械寿命:500万次以上
9. 防护等级:IP40
10. 使用温度范围:-25~+85℃(60%RH以下)(无结冰、无凝露)
11. 使用环境湿度:+5~+35℃时(85%RH以下)

运行特性参数		
序号	用语(略称)	标准
(A)	动作力(DF)	90±20gf
(B)	回复力(RF)	15gf Min
(C)	动作位置(OP)	3.20±0.2mm
(D)	应差距离(OD)	0.12mm Max
(E)	行程(PT)	0.2±0.4mm
(F)	过行程(OT)	0.1mm Min

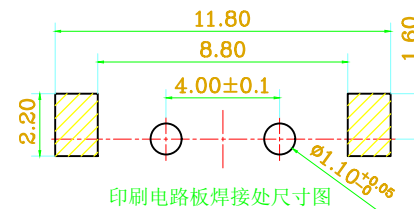

ITEM	DESCRIPTION	MATERIAL	QTY	FINISH/COLOR					
6	导芯	LCP	1	黑色					
5	盖子	尼龙	1	黑色	GENERAL TOLERANCE				
4	弹片	铜合金	1	素材	≥0~2<	±0.15	SCALE		
3	触点	银合金	1	素材	DESIGN	WANGGUIFA	2018.06.12	≥2~5<	±0.25
2	底座	LCP	1	黑色	CHECKED	ZHENGUILAN	2018.06.12	≥0~2<	±0.15
1	端子	黄铜	2	镀银	APPROVED	LILIANJIANG	2018.06.14	≥5	±0.35

FIRST VIEW

The copyright belongs to samzo parts [China] Co., Ltd. please use the material after samzo parts agree to authorize. The final right of interpretation belongs to samzo parts. WWW.KKK-JP.COM

SAMZO COMPONENTS
 Electronic switch and connector manufacturer

TITLE: 8.6*4.8*3.0微型贴片开关
DWG NO: 4ACA-KM6
PART NO: 4ACA240311
MODEL NO: 4ACABYHF
NAME: MICRO SWITCH

