




1. FIGURE AND DIMENSIONS (视图及尺寸)

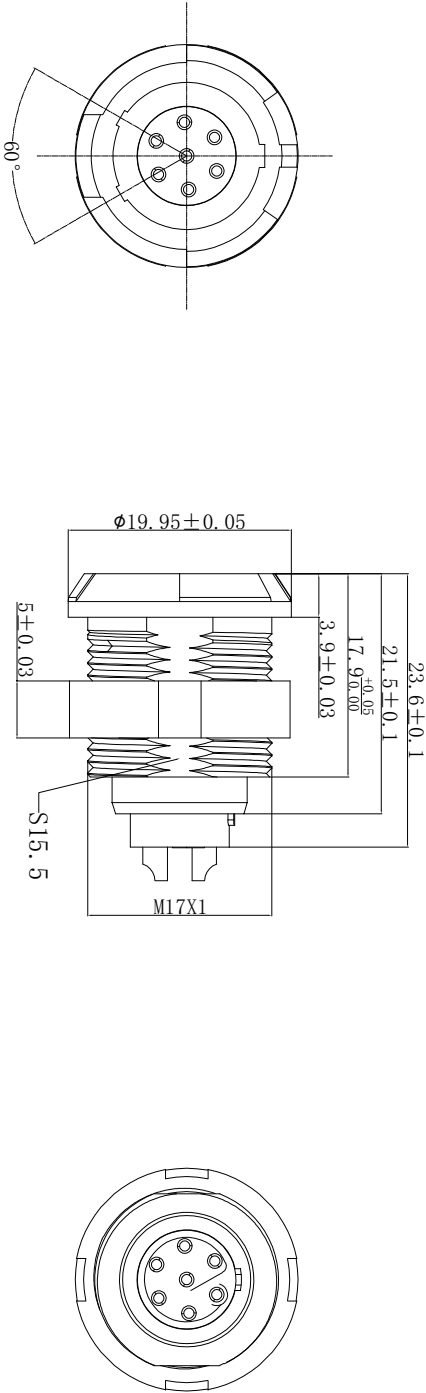

Main technical indicators (主要技术指标)	
1. Mating (插拔次数)	5000
2. Working Temperature (温度)	-55~+150°
3. IP Rating (防护级别)	IP 50
4. Diameter of socket end(插座端直径)	ø 1.3
5. Rated voltage (额定电压)	1650V
6. Rated Current (额定电流)	11A
7. Shell material (壳体材质)	PC
8. Pin Material (插针材料)	Copper alloy gold plating(铜合金镀金)
9. Insulation resistance (绝缘电阻)	>100MΩ
10. Insulator material (绝缘体材料)	L: PPS, P: PEEK
11. Salt spray test (盐雾测试)	> 72H

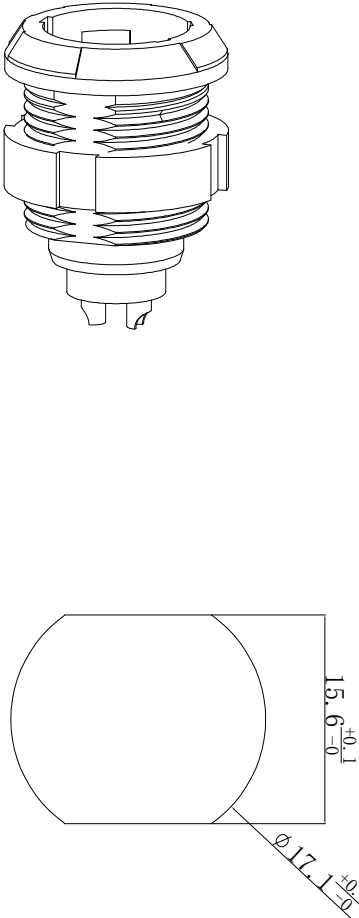

Sum up (总结)	
Series (系列)	M19
Shell style/model (外壳样式/型号)	LPAG: Straight plug, cable collet and nut for fitting a bend relief直塞、电缆夹头和螺母，用于安装弯曲凸起
Button (按键)	3 button(3个按键)
Termination type (终止类型)	Female solder (母焊锡)
Line diameter awg(线材直径)	14WG-28AWG
Matching parts(配件)	LPAB, M1. 7, GLAXXH
14. Nut color (螺帽颜色)	G=灰色/J=黄色/A=蓝色/N=黑色/R=红色/V=绿色/B=白色

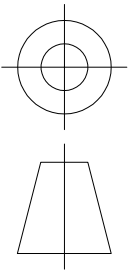版本		TITLE		DRAWING NO.		REV.	
REVA4		LCAB. M1. 7. GLAG		mm		AO	
REVA3							
REVA2							
REVA1							
DRAW		PART NO.		IOF N			
CHECK							
APPR'D							
		USE		XKB INDUSTRIAL PRECISION CO., LIMITED			