

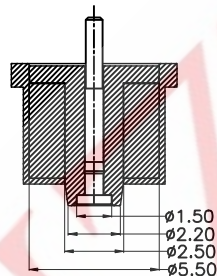
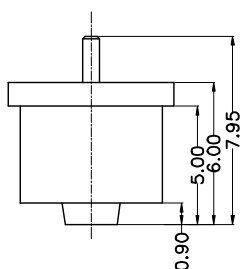
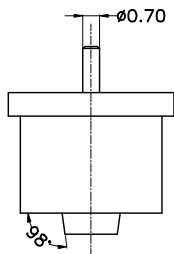
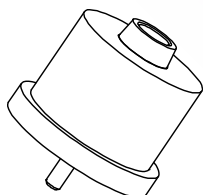



E	1		2		3		4		5		6		7		8	
	POGO PIN		REAC/ROHS								REV	ECN NO	DESCRIPTION	DESIGN	APPROVAL	DATE
											A1	NEW	Replace frame			2018.06.12
D																
C																
B																
A																

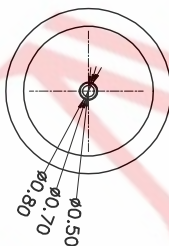

- Notes:
- Characteristics:
- A. Material (材料)
- 1) Housing: High Plastic BLACK (UL94V-0)
 - 2) Plunger: brass c3604
- B. Plating (镀层)
- 1) Plunger: Brass, Plating 3u' Au over Min. 50u' Ni.
- C. Electrical (电气性能)
- 1) Operating voltage: 12V Max.
 - 2) Operating current: 1A Max.
 - 3) Contact resistance: 30mohm Max. at working height (Quiescence).
- D. Environmental (环境性能)
- 1) Storage and operating temperature range: -40°C ~ +85°C
 - 2) Humidity range: 10% RH to 90% RH
 - 3) Salt spray: 48H
- E. Others (其他)
- 1) The dimensions marked * are critical, Should be checked in production
 - 2) RoHS compliant product.

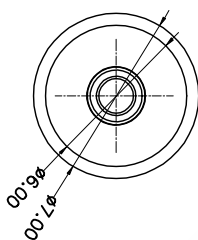

 FIRST VIEW



The copyright belongs to samzo parts [China] Co., Ltd. please use the material after samzo parts agree to authorize. The final right of interpretation belongs to samzo parts.
WWW.KKK-JP.COM

TITLE::

6MM 圆形 PA5.0 H7.95

DWG NO: GA0116-P001

PART NO: GA0116231173

MODEL NO: PG6L-6019-C-H

NAME:

POGO PIN

GENERAL TOLERANCE

≥0~2< ±0.15

≥2~5< ±0.25

≥0~2< ±0.15

≥5 ±0.35

SAMZO COMPONENTS

Electronic switch and connector manufacturer

SCALE

1:1

UNIT

mm