





- Family of 2-wire Common Mode Chokes
- Low profile surface mount package
- Range suited for many DSL and Telecom applications
- Operating Temperature: 0°C to +70°C
- Current rating : 420mA Max($\Delta T \leq 40^\circ\text{C}$)




PGT0402-04

Electrical Specification @25°C	
OCL:	PIN1-4 = PIN2-3 = 4.7mH +50%/-30% @10KHz/0.1V
Inductance imbalance	PIN1-2 = 0.6uH Max.(PIN3-4 Short) @100KHz/0.1V
Hi-POT :	500VAC
Turn Ratio:	1:1±3%
D.C.R:	PIN1-4 = PIN2-3 = 0.8ohm Max.

Dimensions

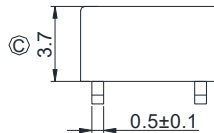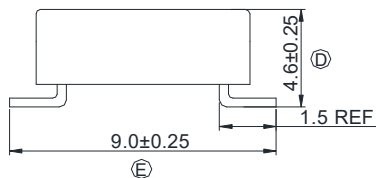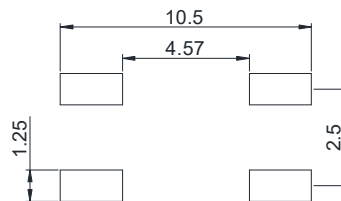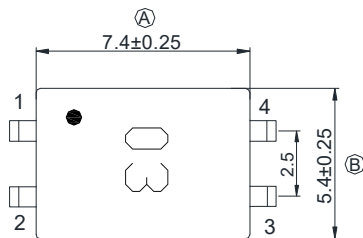

Schematic

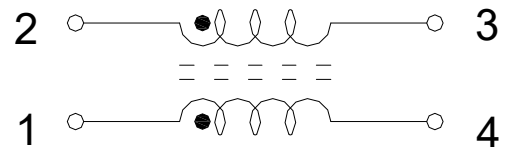

(Units: mm, Unless otherwise specified, all tolerances are ± 0.25)